

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0150320621

Status:


Active

Overview:

FFC Cable Jumpers, Premo-Flex Flat-Flexible Cable Jumpers

Description:

0.30mm Pitch, Premo-Flex FPC Jumper with Latching Ears, Same Side Contacts (Type A), 153.00mm Cable Length, Gold (Au) Plating, 21 Circuits

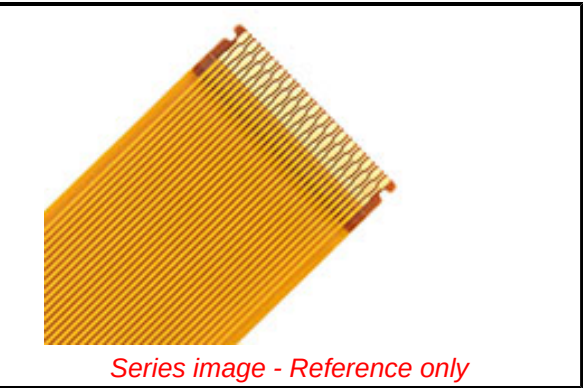

Documents:	
Drawing (PDF)	Datasheet (PDF)
Product Specification 150320001-000 (PDF)	RoHS Certificate of Compliance (PDF)

General	
Product Family	Cable
Series	15032
Crimp Quality Equipment	Yes
Overview	FFC Cable Jumpers, Premo-Flex Flat-Flexible Cable Jumpers
Product Name	Premo-Flex FFC Jumper
UPC	195842789524
Physical	
Cable Length	152.00mm
Circuits (Loaded)	21
Circuits (maximum)	21
Contact Layout Type	A (same side)
Material - Plating Mating	Gold
Packaging Type	Bag
Pitch - Mating Interface	0.30mm
Temperature Range - Operating	-40° to +105°C
Wire Size AWG	N/A
Wire/Cable Type	Flexible Printed Circuitry
Electrical	
Current - Maximum per Contact	0.2A
Voltage - Maximum	N/A
Material Info	
Reference - Drawing Numbers	
Product Specification	150320001-000
Sales Drawing	150320001-000

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per - D(2022)4187-DC (10 June 2022)	
Halogen-Free	
Status	
Low-Halogen	
For more information, please visit Contact US	
China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

15032 Series

Mates With

Easy-On FPC Connector 503566

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION