


Category 6A Shielded Keystone Jack

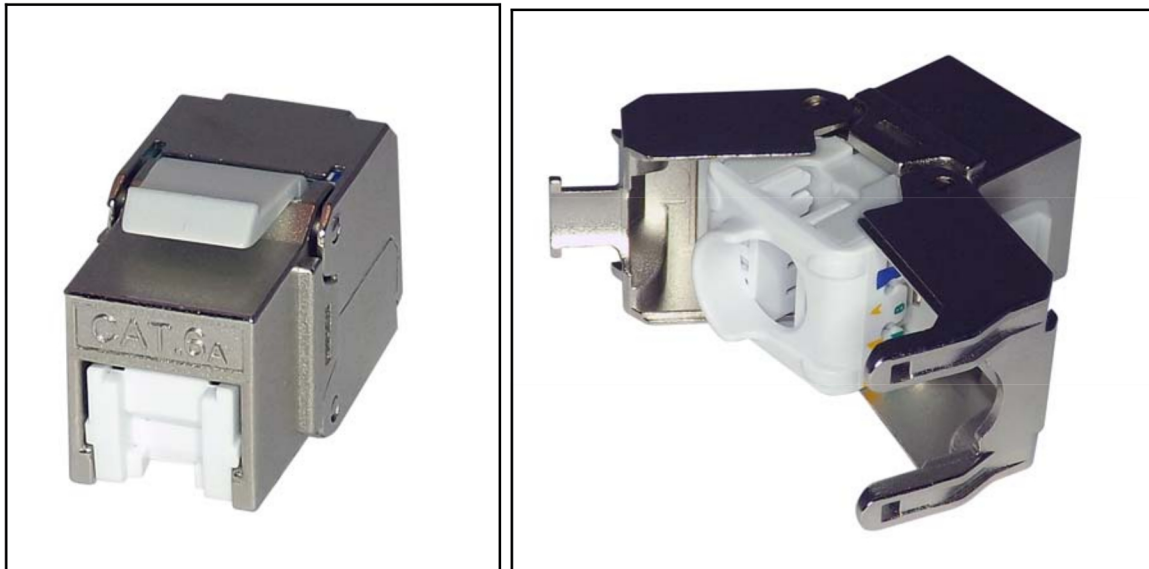

Category 6A Shielded Keystone Jack (SGKSje)

Our die-cast fully shielded Category 6A jack offers a toolless keystone solution for almost any Category 5e, Category 6 or Category 6A STP requirement

Features

- High performance compliant with ANSI/TIA 568 C.2 standard at permanent link level
- Compliant with IEC60512-99-001 – suitable for use with IEEE 802.3at (PoE+) applications
- 3rd Party (Delta) verified
- Quick and easy tool-less lever “butterfly” style termination
- Fully shielded die-cast body is robust as well as offering outstanding performance in eliminating alien cross-talk
- Compact housing suitable for use in high density installations e.g. 0.5U panels
- Standard format keystone fits a wide range of panels, adaptors and faceplates
- Suitable for 23-26 AWG stranded and solid wire. (0.40 – 0.57mm)
- Built-in dustcover
- Panel mount, D UNIVERSAL and DIN rail mountable versions also available

Specifications

- Weight: 22g approx
- Dimensions: 37.8 x 22 x 16.8mm approx.

- Colour: Silver
- Materials: Zinc alloy housing; 50µ"/1.27µm gold plating over nickel over phosphor bronze on contacts
- Plug insertion life: > 750 insertions
- Supplied with cable tie
- Operating temperature: -10°C to 60°C

NB Flush cutter must be used to trim cores

Packaging: **SGKSje:** Packed in individual polybags then in bags of 20
SGKSje#50: Packed in a carton of 50

EAN:

SGKSje: 5055386507211
SGKSjepm: 5055386507228
SGKSjeDINS: 5055386507235
SGKSjeDSpm: 5055386507242
SGKSje#50: 5055386510150

Commodity Code: 85444920

