

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0150320215](#)
Status: **Active**
Overview: FFC Cable Jumpers, Premo-Flex Flat-Flexible Cable Jumpers
Description: 0.30mm Pitch, Premo-Flex FPC Jumper with Latching Ears, Same Side Contacts (Type A), 51.00mm Cable Length, Gold (Au) Plating, 15 Circuits

Documents:

[Drawing \(PDF\)](#) [Datasheet \(PDF\)](#)
[Product Specification 150320001-000 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family Cable
 Series [15032](#)
 Crimp Quality Equipment Yes
 Overview [FFC Cable Jumpers, Premo-Flex Flat-Flexible Cable Jumpers](#)
 Product Name Premo-Flex FFC Jumper
 UPC 195842789111

Physical

Cable Length 51.00mm
 Circuits (Loaded) 15
 Circuits (maximum) 15
 Contact Layout Type A (same side)
 Material - Plating Mating Gold
 Packaging Type Bag
 Pitch - Mating Interface 0.30mm
 Temperature Range - Operating -40° to +105°C
 Wire Size AWG N/A
 Wire/Cable Type Flexible Printed Circuitry


Electrical

Current - Maximum per Contact 0.2A
 Voltage - Maximum N/A

Material Info

Reference - Drawing Numbers

Product Specification 150320001-000
 Sales Drawing 150320001-000

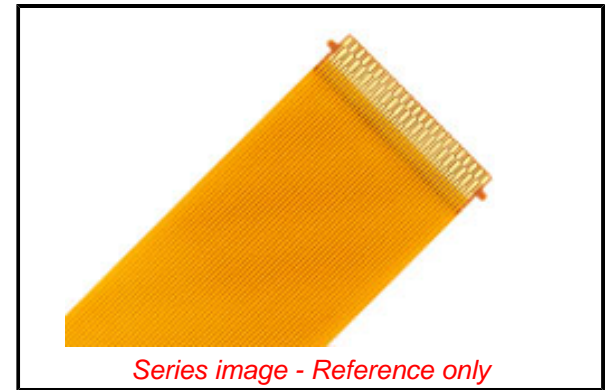

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
 D(2022)4187-DC (10
 June 2022)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[15032 Series](#)

Mates With

Easy-On FPC Connector [503566](#)