

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0150320621](#)
Status: **Active**
Overview: FFC Cable Jumpers, Premo-Flex Flat-Flexible Cable Jumpers
Description: 0.30mm Pitch, Premo-Flex FPC Jumper with Latching Ears, Same Side Contacts (Type A), 153.00mm Cable Length, Gold (Au) Plating, 21 Circuits

Documents:

[Drawing \(PDF\)](#) [Datasheet \(PDF\)](#)
[Product Specification 150320001-000 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	Cable
Series	15032
Crimp Quality Equipment	Yes
Overview	FFC Cable Jumpers, Premo-Flex Flat-Flexible Cable Jumpers
Product Name	Premo-Flex FFC Jumper
UPC	195842789524

Physical

Cable Length	152.00mm
Circuits (Loaded)	21
Circuits (maximum)	21
Contact Layout Type	A (same side)
Material - Plating Mating	Gold
Packaging Type	Bag
Pitch - Mating Interface	0.30mm
Temperature Range - Operating	-40° to +105°C
Wire Size AWG	N/A
Wire/Cable Type	Flexible Printed Circuitry


Electrical

Current - Maximum per Contact	0.2A
Voltage - Maximum	N/A

Material Info

Reference - Drawing Numbers

Product Specification	150320001-000
Sales Drawing	150320001-000

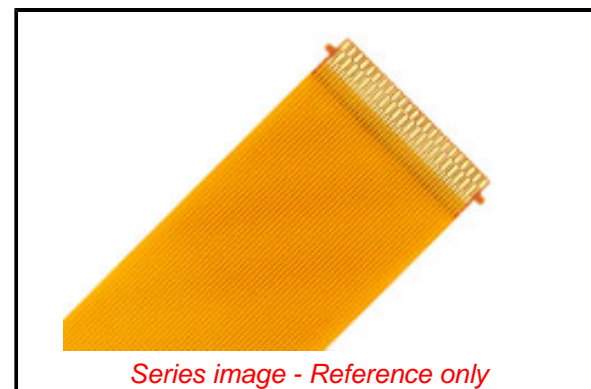

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
D(2022)4187-DC (10
June 2022)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[15032 Series](#)

Mates With

Easy-On FPC Connector [503566](#)