

Han TC100-HMC-MC-CRT-35 mm²-AU

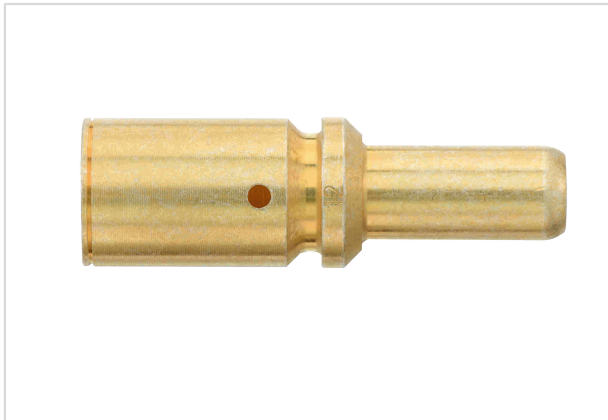


Image is for illustration purposes only. Please refer to product description.

Part number	09 11 200 6135
Specification	Han TC100-HMC-MC-CRT-35 mm ² -AU
HARTING eCatalogue	https://b2b.harting.com/09112006135

Identification

Category	Contacts
Series	TC 100
Type of contact	Crimp contact
Features	lead-free

Version

Gender	Male
Manufacturing process	Turned contacts

Technical characteristics

Conductor cross-section	35 mm ²
Operating current	≤100 A
Contact resistance	≤0.3 mΩ
Stripping length	16 mm
Limiting temperature	-40 ... +125 °C
Mating cycles with other HMC components	≥10,000

Material properties

Material (contacts)	Copper alloy
Surface (contacts)	HMC gold plated



Pushing Performance
Since 1945

Specifications and approvals

Specifications	EN 60664-1 IEC 61984
----------------	-------------------------

Commercial data

Packaging size	10
Net weight	22.6 g
Country of origin	Germany
European customs tariff number	85366990
eCl@ss	27440204 Contact for industrial connectors