


Fibre-optic cable SOOC-DS-P-M4-1-R15

Part number: 552807

FESTO

Suitable for SOE4 fibre-optic units.

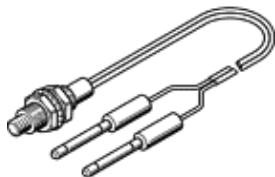

Data sheet

Feature	Value
Materials note	Conforms to RoHS
Measurement method	Diffuse reflection sensor
Minimal object diameter	0.1 mm
Fibre-optic cable - special feature	Precision
Working range	65 mm
Ambient temperature	-55 ... 70 °C
Size, head	M4
Fibre optic cable length	1 m
Min. bending radius	15 mm
Max. tightening torque	2 Nm
Outside diameter	1 mm
Material housing	High alloy steel, non-corrosive
Material fibre-optic	PE
Protection class	IP66
Corrosion resistance classification CRC	1 - Low corrosion stress
PWIS conformity	VDMA24364 zone III