


# ECONOMICAL PLASTIC BATTERY HOLDERS (CONT'D)


## "1/2 AA" Cell -or- "CR2" Cell

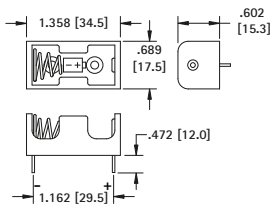

<b>CAT. NO. 2485</b>	PC Mount
<b>CAT. NO. 2485RB</b>	PC Mount w/Ribbon
<b>CAT. NO. 2486</b>	6" Wire Leads
<b>CAT. NO. 2486CN</b>	Wire Leads w/PC Connector


## "1/2AA" - "CR2" - "N" - "12V"

### "N" Cell - 1.5V or "12V" Cell

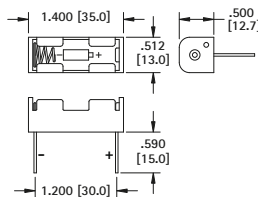

<b>CAT. NO. 2470</b>	PC Mount
<b>CAT. NO. 2470RB</b>	PC Mount w/Ribbon
<b>CAT. NO. 2471</b>	6" Wire Leads
<b>CAT. NO. 2471CN</b>	Wire Leads w/PC Connector

## Two (2) "N" or Two (2) "12V" Cells - In Series

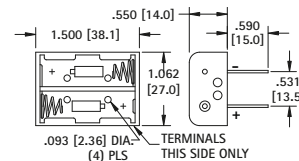

<b>CAT. NO. 2472</b>	PC Mount
<b>CAT. NO. 2472RB</b>	PC Mount w/Ribbon
<b>CAT. NO. 2473</b>	6" Wire Leads
<b>CAT. NO. 2473CN</b>	Wire Leads w/PC Connector

## PLASTIC BATTERY HOLDERS WITH SNAP-ON CONNECTORS

- Same quality features as our wired & PC mount battery holders
- Features separable "Snap-On/Snap-Off" battery connector (9 Volt type) to assure reliable connections
- Easily disconnect battery holder from your device - no tools required
- Batteries securely held in place to maintain a positive contact and a low contact resistance


- Battery contact springs self adjust to variations in battery length
- Mates with Keystone 9 Volt battery straps and connectors (Refer to pages 36)

### SPECIFICATIONS

**Holder:** Polypropylene  
**Male/Female Contacts:** Brass, Nickel Plate  
**Springs:** Spring Steel, Nickel Plate


### "AA"

#### Two Cells - in Series

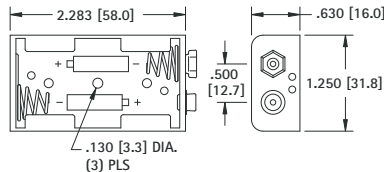


**CAT. NO. 2474**

#### Three (3) Cells - in Series

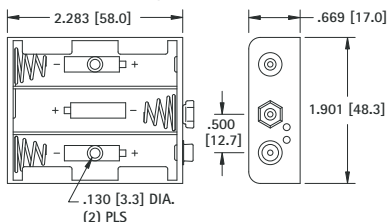

**CAT. NO. 2475**

#### Four (4) Cells - in Series

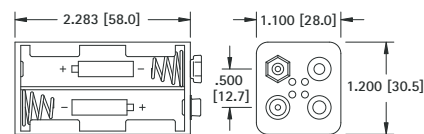

**CAT. NO. 2476**

## PC BATTERY HOLDER CONNECTOR JACKS

- Available in SMT and THM versions
- Vertical and horizontal entry options
- SMT version supplied on tape and reel for vacuum pick and place assembly
- Used to connect any battery holder with PC connector (CN suffix)
- Wiring harness locks onto jack for assured connectivity


### SPECIFICATIONS

**Body:** Nylon 6/6, UL94V-0  
**Pins:** Brass, Tin Plate  
**Current Rating:** 3 Amps, 100V max  
**Temperature Range:** -13°F (-25°C) to 185°F (85°C)

### SMT

SUPPLIED ON TAPE AND REEL


#### VERTICAL

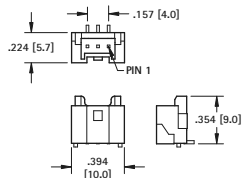

**CAT. NO. 974**

Tape and Reel Spec's: 13 inch reel (500 pieces per reel)

#### HORIZONTAL

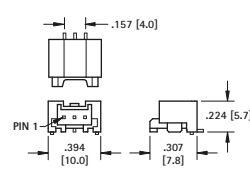


**CAT. NO. 976**

Tape and Reel Spec's: 13 inch reel (1000 pieces per reel)


### THM

#### VERTICAL

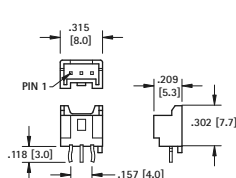

**CAT. NO. 975**

#### HORIZONTAL

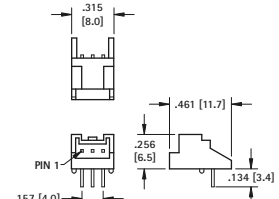

**CAT. NO. 977**