


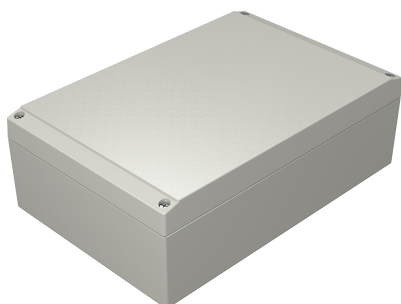

04162408

Aluminium Enclosure Aluform

160 x 240 x 81 mm

Aluminium Enclosure Aluform 160 x 240 x 81 mm

[Catalogues](#)[Assembly instructions](#)[Declaration of Conformity](#)[Drawing](#)[3D Data](#)[Assignmentplan](#)[Terminal Mounting](#)

Technical data

Height	160 mm
Width	240 mm
Depth	81 mm
Material	Aluminium
Material quality	DIN EN 1706 EN AC-AISI 12 (Fe)
Colour	Agate grey (RAL 7038)
Ingress protection	IP66
Degree of protection norm	EN 60529
Impact strength	IK09
temperature min.	-60 °C
temperature max.	130 °C
Seal material	PU (polyurethane) (standard)
Flame spread, sideways	HL 3
Rate of head dispersion	HL 3
Other versions on request	EMV, SBG, SWB, SBGL
Special colours on request	TRUE
Approvals	Lloyd Register, Maritime Register, UL 508A

Commercial data

Country of origin	IN
Order unit	1 Piece
Customs tariff number	85369095
Weight	1.449
GTIN	4250157901187

ETIM classification

ETIM 8	EC000058
--------	----------

ROSE SYSTEMTECHNIK GMBH
Erbeweg 13-15
32457 Porta Westfalica, Germany

Tel.: +49 571 50 41-0
Fax: +49 571 50 41-6
Mail: rose@rose-pw.de

Accessories



04000010

Aluform External hinges



04000020

Aluform Lid safety strip



04000160

Aluform External mounting bracket 160



10011065

Mounting plate for 04.162408



10061484

DIN rail 35/7,5 for 04 162408