


SPT 300

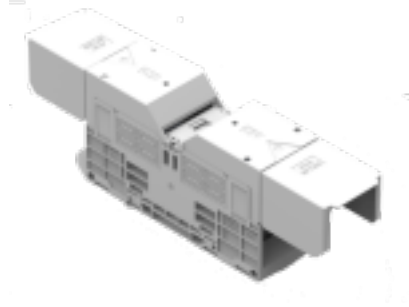

Approvals



General Data

Type	SPT 300
Wire Termination Technology	Nut Bolt Connection
Ratings	1500 V/520 A/300 sq mm/25 Nm
GTIN / Harmonize Custom Code	85389000
Standard Packing Qty (in No)	10
Country of Origin	India
Screw Size	M16

Dimensions & Weight

Height (mm)	89.30
Height (inches)	3.50
Width (mm)	276.80
Width (inches)	10.86
Thickness (mm)	55
Weight For Standard Packing Qty (Kg)	7.00

Material Data

Housing	PA 6,6
Standard Colour	Grey
Other Color Variants	Black, Blue, Green, Khakhi, Red, Yellow

Rated Conductor Size

Stranded Wire - min (sq mm)	25
Stranded Wire - max (sq mm)	300
Solid Wire - min (sq mm)	25
Solid Wire - max (sq mm)	300

Ratings - IEC

Standard	IEC 60947-7-1
Rated Voltage (V)	1500
Rated Current (A)	520
Rated Cross Section (sq mm)	300
Short Time Withstand Current (kA)	36
Rated Impulse Withstand Voltage(kV)	8
Pollution Degree	III

Accessories

End Clamp

SCUDD

Height : 50 mm

Width : 55.50 mm

Thickness : 10 mm

