

Accessories

End Plate

KPSLD

Height : 46.40 mm
Width : 85.10 mm
Thickness : 1 mm



Partition Plate With Foot

BPSCA

(Partition Plate-End clamp combo with knob)

Height : 74 mm
Width : 90 mm



KBFA

(Partition Plate with knob)

Height : 76.6 mm
Width : 90 mm



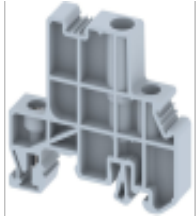
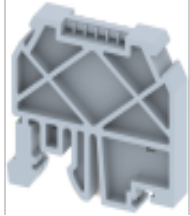
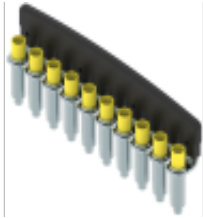
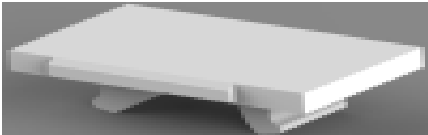
Barrier Plate

DBF-6

Height : 77 mm
Width : 85 mm
Thickness : 3 mm



End Clamp

SCUDD Height : 50 mm Width : 55.50 mm Thickness : 10 mm	
SCUSL Height : 41 mm Width : 47.50 mm Thickness : 8 mm	
Comb-type Shorting Link	
SLD6 (2W, 3W, 4W, 5W, 10W)	
Cross Connection Insulated Link Assembly	
CCLAKG6 (2 Way, 3 Way, 4 Way, 5 Way, 6 Way, 10 Way)	
Marking Label	
LABEL KN8	

Mounting Channel (Standard Lengths 300 mm, 500 mm, 1000 mm)

CHK

Height : 7.5 mm

Width : 35 mm

Thickness : 1 mm



CHKDS (Perforated)

Height : 15 mm

Width : 35 mm

Thickness : 1.50 mm



CHKS (Perforated)

Height : 7.5 mm

Width : 35 mm

Thickness : 1 mm



CHS

Height : 15 mm

Width : 32 mm

Thickness : 1.50 mm



Group Marking Holder

GMH 10

Height : 51 mm

Width : 41.50 mm

Thickness : 10 mm



GMH 20 Height : 51 mm Width : 41.50 mm Thickness : 20 mm	
PVC Transparent Protection cover	
BPSCACP Height : 42 mm Width : 90 mm Thickness : 1 mm	
PCPDBF-6 Height : 13 mm Width : 90 mm Thickness : 1 mm	

Note : Technical specifications may change in line with technical advances and industry standards