


## KULTD 6

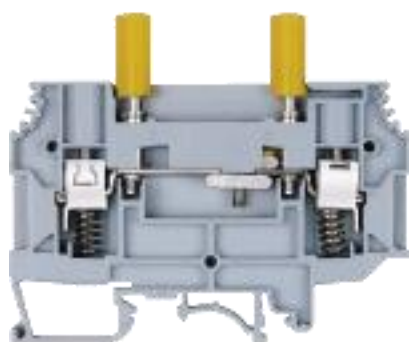

### Approvals



### General Data

Type	KULTD 6
Wire Termination Technology	Screw Clamp
Ratings	1000 V/41 A/6 sq mm/1/0 Nm
GTIN / Harmonize Custom Code	India
Standard Packing Qty (in No)	50
Country of Origin	India
Screw Size	M3.5

### Dimensions & Weight

Height (mm)	56
Height (inches)	2.20
Width (mm)	85.50
Width (inches)	3.35
Thickness (mm)	8
Weight For Standard Packing Qty (Kg)	2.05

## Material Data

Housing	PA 6,6
Standard Colour	Grey
Other Color Variants	Black, Blue, Green, Khakhi, Red, Yellow

## Rated Conductor Size

Stranded Wire - min (sq mm)	0.5
Stranded Wire - max (sq mm)	6
Solid Wire - min (sq mm)	0.5
Solid Wire - max (sq mm)	10

## Ratings - IEC

Standard	EC 60947-7-1
Rated Voltage (V)	1000
Rated Current (A)	41
Rated Cross Section (sq mm)	6
Short Time Withstand Current (kA)	0.72
Rated Impulse Withstand Voltage(kV)	6
Pollution Degree	III

# Accessories


## End Plate

### KPSLD

**Height : 46.40 mm**

**Width : 85.10 mm**

**Thickness : 1 mm**

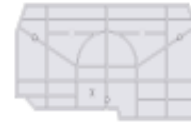


## End Clamp

### SCUDD

**Height : 50 mm**

**Width : 55.50 mm**

**Thickness : 10 mm**

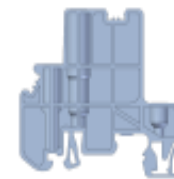

### SCUSL

**Height : 41 mm**

**Width : 47.50 mm**

**Thickness : 8 mm**



## Comb-type Shorting Link

**SLD6**  
( 2W, 3W, 4W, 5W, 10W )



## Marking Label

**LABEL KN8**



## Mounting Channel (Standard Lengths 300 mm, 500 mm, 1000 mm)

**CHK**

Height : 7.5 mm  
Width : 35 mm  
Thickness : 1 mm



**CHKDS (Perforated)**

Height : 15 mm  
Width : 35 mm  
Thickness : 1.50 mm



**CHKS (Perforated)**

Height : 7.5 mm  
Width : 35 mm  
Thickness : 1 mm



