

LT series

- Downsize and long life series
- Endurance: 5,000 hours at 105°C
- Compliant to AEC-Q200
- RoHS Compliant




SPECIFICATIONS


Items	Characteristics		
Category Temperature Range	-25~+105°C		
Rated Voltage Range	160~550Vdc		
Capacitance Tolerance	$\pm 20\%$ (M) (at 20°C, 120Hz)		
Leakage Current	$I \leq 3\sqrt{CV}$ Where, I:Max.leakage current (μ A),C:Nominal capacitance (μ F),V: Rated voltage (V)	160~400	420~550
Dissipation Factor (tanδ)	Rated Voltage(Vdc)	160~400	420~550
	Dissipation Factor(Max.)	0.15	0.20
Low Temperature Characteristics (Max.Impedance Ratio)	Rated Voltage(Vdc)	160~250	315~550
	$Z(-25^\circ\text{C})/Z(+20^\circ\text{C})$	4	8
	The following specifications shall be satisfied when the capacitors are restored to 20°C after DC voltage plus the rated ripple current is applied for 5,000 hours at 105°C.		
Endurance	Capacitance Change	$\leq 20\%$ of the initial value	
	Dissipation Factor	$\leq 200\%$ of the initial specified value(500~550Vdc: $\leq 250\%$)	
	Leakage Current	\leq The initial specified value	
	The following specifications shall be satisfied when the capacitors are restored to 20°C after exposing them for 1,000 hours at 105°C without voltage applied.		
Shelf Life	Capacitance Change	$\leq 15\%$ of the initial value	
	Dissipation Factor	$\leq 150\%$ of the initial specified value	
	Leakage Current	$\leq 200\%$ of the initial specified value	

DIMENSIONS[mm]


- Terminal Code : K (Φ22 to Φ35) : Standard

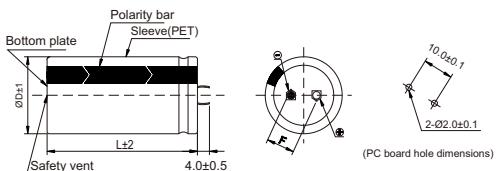


- Terminal Code : T (Φ25 to Φ35) : Standard

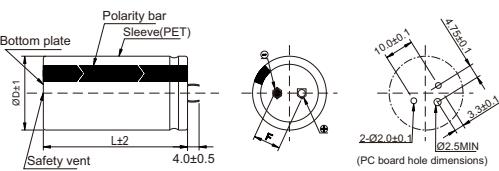


- Terminal Code: P (Φ35 to Φ45): Standard

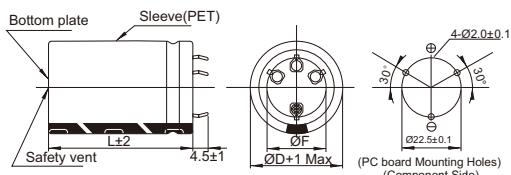

- Terminal Code : L(Φ35) : Standard

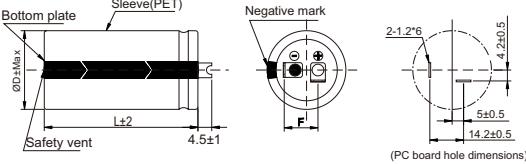

PART NUMBERING SYSTEM

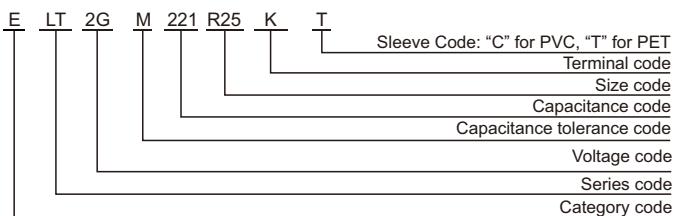

RATED RIPPLE CURRENT MULTIPLIERS

Frequency correction factor for ripple current(Hz)

W.V	120	1k	10k	100k
160~250	1.00	1.32	1.45	1.50
315~550	1.00	1.30	1.41	1.43

LT series

■ STANDARD RATINGS

WV (V _{dc})	Cap (μF)	Size ΦDxL(mm)	tanδ	Rated ripple current (A _{rms} /105°C, 120Hz)	Part Number
160	390	22x25	0.15	1.32	ELT2CM391O25KT
	470	25x25	0.15	1.48	ELT2CM471P25KT
	560	22x30	0.15	1.66	ELT2CM561O30KT
	560	25x25	0.15	1.68	ELT2CM561P25KT
	560	25x30	0.15	1.74	ELT2CM561P30KT
	680	22x35	0.15	1.87	ELT2CM681O35KT
	680	25x30	0.15	1.88	ELT2CM681P30KT
	680	30x25	0.15	1.96	ELT2CM681Q25KT
	820	22x40	0.15	2.09	ELT2CM821O40KT
	820	22x45	0.15	2.18	ELT2CM821O45KT
	1000	22x50	0.15	2.41	ELT2CM102O50KT
	1000	25x40	0.15	2.38	ELT2CM102P40KT
	1000	30x30	0.15	2.40	ELT2CM102Q30KT
	1000	35x25	0.15	2.55	ELT2CM102R25KT
	1200	25x45	0.15	2.71	ELT2CM122P45KT
	1200	30x40	0.15	2.77	ELT2CM122Q40KT
	1200	35x30	0.15	2.86	ELT2CM122R30KT
	1500	25x50	0.15	3.08	ELT2CM152P50KT
	1500	30x45	0.15	3.17	ELT2CM152Q45KT
	1500	35x35	0.15	3.22	ELT2CM152R35KT
	1800	30x50	0.15	3.53	ELT2CM182Q50KT
	1800	35x40	0.15	3.66	ELT2CM182R40KT
	2200	35x45	0.15	4.14	ELT2CM222R45KT
	2700	35x50	0.15	4.68	ELT2CM272R50KT
180	330	22x25	0.15	1.21	ELT2LM331O25KT
	470	22x30	0.15	1.52	ELT2LM471O30KT
	470	25x25	0.15	1.52	ELT2LM471P25KT
	560	22x35	0.15	1.70	ELT2LM561O35KT
	560	25x30	0.15	1.78	ELT2LM561P30KT
	680	22x40	0.15	1.91	ELT2LM681O40KT
	680	25x30	0.15	1.88	ELT2LM681P30KT
	820	22x45	0.15	1.99	ELT2LM821O45KT
	820	25x35	0.15	2.16	ELT2LM821P35KT
	820	30x30	0.15	2.17	ELT2LM821Q30KT
	820	35x25	0.15	2.31	ELT2LM821R25KT
	1000	22x50	0.15	2.25	ELT2LM102O50KT
	1000	25x45	0.15	2.47	ELT2LM102P45KT
	1000	30x35	0.15	2.46	ELT2LM102Q35KT
	1200	25x50	0.15	2.75	ELT2LM122P50KT
	1200	30x40	0.15	2.77	ELT2LM122Q40KT
	1200	35x30	0.15	2.86	ELT2LM122R30KT
	1500	30x50	0.15	3.22	ELT2LM152Q50KT
	1500	35x35	0.15	3.22	ELT2LM152R35KT
	1800	35x45	0.15	3.74	ELT2LM182R45KT
	2200	35x50	0.15	4.22	ELT2LM222R50KT
200	270	22x25	0.15	1.10	ELT2DM271O25KT
	330	22x30	0.15	1.22	ELT2DM331O30KT
	330	25x25	0.15	1.22	ELT2DM331P25KT

WV (V _{dc})	Cap (μF)	Size ΦDxL(mm)	tanδ	Rated ripple current (A _{rms} /105°C, 120Hz)	Part Number
200	390	22x30	0.15	1.38	ELT2DM391O30KT
	390	25x25	0.15	1.39	ELT2DM391P25KT
	470	22x35	0.15	1.55	ELT2DM471O35KT
	470	22x40	0.15	1.62	ELT2DM471O40KT
	470	25x30	0.15	1.58	ELT2DM471P30KT
	470	30x25	0.15	1.55	ELT2DM471Q25KT
	560	22x40	0.15	1.73	ELT2DM561O40KT
	560	22x45	0.15	1.78	ELT2DM561O45KT
	560	25x30	0.15	1.71	ELT2DM561P30KT
	560	30x25	0.15	1.78	ELT2DM561Q25KT
	680	22x45	0.15	1.81	ELT2DM681O45KT
	680	25x35	0.15	1.87	ELT2DM681P35KT
	680	30x30	0.15	1.98	ELT2DM681Q30KT
	680	35x25	0.15	2.10	ELT2DM681R25KT
	820	22x50	0.15	2.18	ELT2DM821O50KT
	820	25x40	0.15	2.09	ELT2DM821P40KT
	820	30x30	0.15	2.10	ELT2DM821Q30KT
	820	30x35	0.15	2.22	ELT2DM821Q35KT
	1000	25x50	0.15	2.39	ELT2DM102P50KT
	1000	30x35	0.15	2.40	ELT2DM102Q35KT
	1000	30x40	0.15	2.53	ELT2DM102R40KT
	1000	35x30	0.15	2.61	ELT2DM102R30KT
	1000	35x35	0.15	2.72	ELT2DM102R35KT
	1200	30x50	0.15	2.88	ELT2DM122Q50KT
	1200	35x35	0.15	2.88	ELT2DM122R35KT
220	1500	30x50	0.15	2.92	ELT2DM152Q50KT
	1500	35x40	0.15	2.96	ELT2DM152R40KT
	1800	35x50	0.15	3.12	ELT2DM182R50KT
	2200	35x55	0.15	3.34	ELT2DM222R55KT
	2700	35x60	0.15	3.50	ELT2DM272R60KT
	270	22x25	0.15	1.10	ELT2NM271O25KT
	330	22x30	0.15	1.19	ELT2NM331O30KT
	390	25x30	0.15	1.39	ELT2NM391P30KT
	470	22x40	0.15	1.55	ELT2NM471O40KT
	470	25x30	0.15	1.56	ELT2NM471P30KT
	470	30x25	0.15	1.63	ELT2NM471Q25KT
	560	22x45	0.15	1.73	ELT2NM561O45KT
	560	30x30	0.15	1.79	ELT2NM561Q30KT
	680	22x50	0.15	1.99	ELT2NM681O50KT
	680	25x40	0.15	1.96	ELT2NM681P40KT
	680	30x35	0.15	2.02	ELT2NM681Q35KT
	820	25x45	0.15	2.24	ELT2NM821P45KT
	820	30x40	0.15	2.29	ELT2NM821Q40KT
	820	35x30	0.15	2.36	ELT2NM821R30KT
	1000	30x45	0.15	2.59	ELT2NM102Q45KT
	1000	35x35	0.15	2.63	ELT2NM102R35KT
	1200	30x50	0.15	2.88	ELT2NM122Q50KT
	1200	35x40	0.15	2.98	ELT2NM122R40KT
	1500	35x45	0.15	3.41	ELT2NM152R45KT
	1800	35x50	0.15	3.82	ELT2NM182R50KT

Snap-in&Lug
Terminal Type

LT series

■ STANDARD RATINGS

WV (V _{dc})	Cap (μF)	Size ΦDxL(mm)	tanδ	Rated ripple current (Arms/105°C, 120Hz)	Part Number
250	220	22x25	0.15	1.01	ELT2EM221O25KT
	220	22x35	0.15	1.10	ELT2EM221O35KT
	220	25x25	0.15	1.10	ELT2EM221P25KT
	270	22x30	0.15	1.20	ELT2EM271O30KT
	330	22x30	0.15	1.32	ELT2EM331O30KT
	330	25x25	0.15	1.32	ELT2EM331P25KT
	330	30x25	0.15	1.32	ELT2EM331Q25KT
	390	22x35	0.15	1.44	ELT2EM391O35KT
	390	22x45	0.15	1.44	ELT2EM391O45KT
	390	25x30	0.15	1.43	ELT2EM391P30KT
	390	25x35	0.15	1.51	ELT2EM391P35KT
	390	30x25	0.15	1.51	ELT2EM391Q25KT
	470	22x40	0.15	1.62	ELT2EM471O40KT
	560	22x50	0.15	1.84	ELT2EM561O50KT
	560	25x40	0.15	1.78	ELT2EM561P40KT
	560	30x30	0.15	1.83	ELT2EM561Q30KT
	560	35x25	0.15	1.91	ELT2EM561R25KT
	680	25x45	0.15	2.04	ELT2EM681P45KT
	680	30x35	0.15	2.06	ELT2EM681Q35KT
	680	30x40	0.15	2.15	ELT2EM681Q40KT
	680	35x30	0.15	2.15	ELT2EM681R30KT
	680	35x35	0.15	2.20	ELT2EM681R35KT
	820	25x50	0.15	2.28	ELT2EM821P50KT
	820	30x40	0.15	2.28	ELT2EM821Q40KT
	820	30x45	0.15	2.39	ELT2EM821Q45KT
	820	35x35	0.15	2.38	ELT2EM821R35KT
	1000	30x50	0.15	2.68	ELT2EM102Q50KT
	1000	35x40	0.15	2.72	ELT2EM102R40KT
	1200	30x50	0.15	2.80	ELT2EM122Q50KT
	1200	35x45	0.15	2.82	ELT2EM122R45KT
	1500	35x50	0.15	3.12	ELT2EM152R50KT
	1800	35x60	0.15	3.36	ELT2EM182R60KT
315	100	22x25	0.15	0.64	ELT2FM101O25KT
	150	22x25	0.15	0.80	ELT2FM151O25KT
	180	22x30	0.15	0.92	ELT2FM181O30KT
	180	25x25	0.15	0.94	ELT2FM181P25KT
	220	22x35	0.15	1.04	ELT2FM221O35KT
	220	30x25	0.15	1.17	ELT2FM221Q25KT
	270	22x40	0.15	1.18	ELT2FM271O40KT
	270	25x30	0.15	1.19	ELT2FM271P30KT
	330	22x45	0.15	1.33	ELT2FM331O45KT
	330	25x35	0.15	1.37	ELT2FM331P35KT
	330	30x30	0.15	1.40	ELT2FM331Q30KT
	330	35x25	0.15	1.49	ELT2FM331R25KT
	390	22x50	0.15	1.48	ELT2FM391O50KT
	390	25x40	0.15	1.52	ELT2FM391P40KT
	470	25x45	0.15	1.70	ELT2FM471P45KT
	470	30x35	0.15	1.71	ELT2FM471Q35KT
	470	35x30	0.15	1.82	ELT2FM471R30KT

WV (V _{dc})	Cap (μF)	Size ΦDxL(mm)	tanδ	Rated ripple current (Arms/105°C, 120Hz)	Part Number
315	560	30x45	0.15	1.97	ELT2FM561Q45KT
	560	35x35	0.15	2.00	ELT2FM561R35KT
	680	30x50	0.15	2.21	ELT2FM681Q50KT
	680	35x40	0.15	2.29	ELT2FM681R40KT
	820	35x45	0.15	2.57	ELT2FM821R45KT
	1000	35x50	0.15	2.89	ELT2FM102R50KT
	1200	35x60	0.15	3.02	ELT2FM122R60KT
	1500	35x70	0.15	3.38	ELT2FM152R70KT
	120	22x25	0.15	0.72	ELT2VM121O25KT
	150	22x30	0.15	0.84	ELT2VM151O30KT
350	180	25x25	0.15	0.94	ELT2VM181P25KT
	220	22x40	0.15	1.06	ELT2VM221O40KT
	220	25x30	0.15	1.07	ELT2VM221P30KT
	220	30x25	0.15	1.13	ELT2VM221Q25KT
	270	22x45	0.15	1.20	ELT2VM271O45KT
	270	22x50	0.15	1.24	ELT2VM271O50KT
	270	25x35	0.15	1.24	ELT2VM271P35KT
	270	30x30	0.15	1.27	ELT2VM271Q30KT
	270	35x25	0.15	1.35	ELT2VM271R25KT
	330	22x50	0.15	1.36	ELT2VM331O50KT
	330	25x40	0.15	1.39	ELT2VM331P40KT
	330	30x35	0.15	1.43	ELT2VM331Q35KT
	390	25x45	0.15	1.55	ELT2VM391P45KT
	390	30x40	0.15	1.60	ELT2VM391Q40KT
	390	35x30	0.15	1.66	ELT2VM391R30KT
400	470	25x50	0.15	1.72	ELT2VM471P50KT
	470	30x45	0.15	1.81	ELT2VM471Q45KT
	470	35x35	0.15	1.83	ELT2VM471R35KT
	560	30x50	0.15	2.00	ELT2VM561Q50KT
	560	35x40	0.15	2.07	ELT2VM561R40KT
	680	35x45	0.15	2.34	ELT2VM681R45KT
	820	35x50	0.15	2.62	ELT2VM821R50KT
	68	22x25	0.15	0.48	ELT2GM680O25KT
	82	22x25	0.15	0.60	ELT2GM820O25KT
	100	22x25	0.15	0.66	ELT2GM101O25KT
	120	22x30	0.15	0.75	ELT2GM121O30KT
	120	25x25	0.15	0.75	ELT2GM121P25KT
	150	22x35	0.15	0.86	ELT2GM151O35KT
	150	25x30	0.15	0.86	ELT2GM151P30KT
	180	22x35	0.15	0.92	ELT2GM181O35KT
	180	22x40	0.15	0.96	ELT2GM181O40KT
	180	25x30	0.15	0.97	ELT2GM181P30KT
	180	30x25	0.15	1.02	ELT2GM181Q25KT
	220	22x45	0.15	1.09	ELT2GM221O45KT
	220	25x35	0.15	1.12	ELT2GM221P35KT
	220	25x40	0.15	1.15	ELT2GM221P40KT
	270	22x50	0.15	1.15	ELT2GM221Q30KT
	270	25x40	0.15	1.25	ELT2GM271P40KT

LT series

■ STANDARD RATINGS

WV (V _{dc})	Cap (μF)	Size ΦDxL(mm)	tanδ	Rated ripple current (Arms/105°C, 120Hz)	Part Number
400	270	25x45	0.15	1.29	ELT2GM271P45KT
	270	25x50	0.15	1.32	ELT2GM271P50KT
	270	30x30	0.15	1.27	ELT2GM271Q30KT
	270	30x35	0.15	1.32	ELT2GM271Q35KT
	330	25x45	0.15	1.42	ELT2GM331P45KT
	330	25x50	0.15	1.44	ELT2GM331P50KT
	330	30x35	0.15	1.43	ELT2GM331Q35KT
	330	30x45	0.15	1.52	ELT2GM331Q45KT
	330	35x30	0.15	1.52	ELT2GM331R30KT
	390	30x40	0.15	1.60	ELT2GM391Q40KT
	390	30x45	0.15	1.64	ELT2GM391Q45KT
	390	35x35	0.15	1.67	ELT2GM391R35KT
	470	30x45	0.15	1.84	ELT2GM471Q45KT
	470	30x50	0.15	1.84	ELT2GM471Q50KT
	470	35x40	0.15	1.90	ELT2GM471R40KT
	470	35x45	0.15	2.00	ELT2GM471R45KT
	560	35x45	0.15	2.12	ELT2GM561R45KT
	560	35x50	0.15	2.22	ELT2GM561R50KT
	680	35x50	0.15	2.38	ELT2GM681R50KT
	820	35x50	0.15	2.20	ELT2GM821R50KT
	820	35x55	0.15	2.42	ELT2GM821R55KT
	820	35x60	0.15	2.58	ELT2GM821R60KT
	1000	35x70	0.15	2.86	ELT2GM102R70KT
	1000	35x80	0.15	2.92	ELT2GM102R80KT
	1000	40x80	0.15	3.00	ELT2GM102Y80PT
420	1200	40x80	0.15	3.18	ELT2GM122Y80PT
	1500	40x100	0.15	3.36	ELT2GM152YA0PT
	1800	40x100	0.15	3.58	ELT2GM182YA0PT
	1800	45x100	0.15	3.68	ELT2GM182I0PT
	2200	45x100	0.15	3.82	ELT2GM222I0PT
	2700	45x100	0.15	4.00	ELT2GM272I0PT
	100	22x25	0.20	0.66	ELT2TM101O25KT
	120	22x30	0.20	0.75	ELT2TM121O30KT
	120	25x25	0.20	0.77	ELT2TM121P25KT
	150	22x35	0.20	0.86	ELT2TM151O35KT
	180	22x45	0.20	0.98	ELT2TM181O45KT
	180	25x35	0.20	1.01	ELT2TM181P35KT
	180	30x25	0.20	1.02	ELT2TM181Q25KT
	220	22x50	0.20	1.11	ELT2TM221O50KT
	220	25x40	0.20	1.14	ELT2TM221P40KT
	220	30x30	0.20	1.14	ELT2TM221Q30KT
	220	35x25	0.20	1.22	ELT2TM221R25KT
	270	25x45	0.20	1.29	ELT2TM271P45KT
	270	30x35	0.20	1.30	ELT2TM271Q35KT
	270	35x30	0.20	1.38	ELT2TM271R30KT
	330	25x50	0.20	1.44	ELT2TM331P50KT
	330	30x40	0.20	1.48	ELT2TM331Q40KT
	330	35x35	0.20	1.54	ELT2TM331R35KT

WV (V _{dc})	Cap (μF)	Size ΦDxL(mm)	tanδ	Rated ripple current (Arms/105°C, 120Hz)	Part Number
420	390	30x45	0.20	1.64	ELT2TM391Q45KT
	390	35x40	0.20	1.73	ELT2TM391R40KT
	470	30x45	0.20	1.70	ELT2TM471Q45KT
	470	30x50	0.20	1.84	ELT2TM471Q50KT
	470	35x45	0.20	1.94	ELT2TM471R45KT
	560	35x45	0.20	2.06	ELT2TM561R45KT
	560	35x50	0.20	2.17	ELT2TM561R50KT
	680	35x50	0.20	2.32	ELT2TM681R50KT
	68	22x25	0.20	0.45	ELT2WM680O25KT
	68	22x30	0.20	0.50	ELT2WM680O30KT
450	68	25x25	0.20	0.50	ELT2WM680P25KT
	82	22x25	0.20	0.59	ELT2WM820O25KT
	82	22x30	0.20	0.62	ELT2WM820O30KT
	100	22x30	0.20	0.69	ELT2WM101O30KT
	100	25x25	0.20	0.70	ELT2WM101P25KT
	120	22x30	0.20	0.74	ELT2WM121O30KT
	120	22x35	0.20	0.77	ELT2WM121O35KT
	120	25x25	0.20	0.74	ELT2WM121P25KT
	120	25x30	0.20	0.77	ELT2WM121P30KT
	150	22x35	0.20	0.86	ELT2WM151O35KT
	150	22x40	0.20	0.88	ELT2WM151O40KT
	150	22x45	0.20	0.90	ELT2WM151O45KT
	150	25x30	0.20	0.88	ELT2WM151P30KT
	150	25x35	0.20	0.92	ELT2WM151P35KT
	150	30x25	0.20	0.93	ELT2WM151Q25KT
	180	22x45	0.20	0.98	ELT2WM181O45KT
	180	22x50	0.20	1.01	ELT2WM181O50KT
	180	25x30	0.20	1.00	ELT2WM181P30KT
	180	25x35	0.20	1.02	ELT2WM181P35KT
	180	25x40	0.20	1.03	ELT2WM181P40KT
	180	30x30	0.20	1.03	ELT2WM181Q30KT
	180	35x25	0.20	1.10	ELT2WM181R25KT
	220	22x50	0.20	1.14	ELT2WM221O50KT
	220	25x35	0.20	1.12	ELT2WM221P35KT
	220	25x40	0.20	1.14	ELT2WM221P40KT
	220	25x45	0.20	1.16	ELT2WM221P45KT
	220	30x30	0.20	1.16	ELT2WM221Q30KT
	220	30x35	0.20	1.17	ELT2WM221Q35KT
	220	30x40	0.20	1.20	ELT2WM221Q40KT
	220	35x30	0.20	1.24	ELT2WM221R30KT
	270	25x45	0.20	1.28	ELT2WM271P45KT
	270	25x50	0.20	1.31	ELT2WM271P50KT
	270	30x40	0.20	1.33	ELT2WM271Q40KT
	270	35x30	0.20	1.36	ELT2WM271R30KT
	270	35x35	0.20	1.39	ELT2WM271R35KT
	330	25x50	0.20	1.42	ELT2WM331P50KT
	330	25x55	0.20	1.48	ELT2WM331P55KT
	330	30x40	0.20	1.46	ELT2WM331Q40KT

Snap-in&Lug
Terminal Type

LT series

■ STANDARD RATINGS

WV (V _{dc})	Cap (μF)	Size ΦDxL(mm)	tanδ	Rated ripple current (Arms/105°C, 120Hz)	Part Number
450	330	30x45	0.20	1.51	ELT2WM331Q45KT
	330	35x35	0.20	1.48	ELT2WM331R35KT
	330	35x40	0.20	1.51	ELT2WM331R40KT
	390	30x45	0.20	1.64	ELT2WM391Q45KT
	390	30x50	0.20	1.67	ELT2WM391Q50KT
	390	35x35	0.20	1.60	ELT2WM391R35KT
	390	35x45	0.20	1.77	ELT2WM391R45KT
	470	30x50	0.20	1.80	ELT2WM471Q50KT
	470	35x40	0.20	1.70	ELT2WM471R40KT
	470	35x45	0.20	1.84	ELT2WM471R45KT
	470	35x50	0.20	1.86	ELT2WM471R50KT
	560	30x55	0.20	1.80	ELT2WM561Q55KT
	560	30x60	0.20	1.92	ELT2WM561Q60KT
	560	35x45	0.20	1.80	ELT2WM561R45KT
	560	35x50	0.20	1.92	ELT2WM561R50KT
	560	35x55	0.20	1.94	ELT2WM561R55KT
	680	35x55	0.20	2.04	ELT2WM681R55KT
	680	35x60	0.20	2.10	ELT2WM681R60KT
	820	35x65	0.20	2.35	ELT2WM821R65KT
	820	35x70	0.20	2.40	ELT2WM821R70KT
	1000	35x80	0.20	2.60	ELT2WM102R80KT
	1000	40x65	0.20	2.60	ELT2WM102Y65PT
	1500	45x83	0.20	3.00	ELT2WM152I83PT
500	47	22x25	0.20	0.35	ELT2HM470O25KT
	68	22x25	0.20	0.42	ELT2HM680O25KT
	82	25x25	0.20	0.60	ELT2HM820P25KT
	100	22x35	0.20	0.80	ELT2HM101O35KT
	100	25x30	0.20	0.80	ELT2HM101P30KT
	100	30x25	0.20	0.82	ELT2HM101Q25KT
	120	30x25	0.20	0.88	ELT2HM121Q25KT
	120	30x30	0.20	0.91	ELT2HM121Q30KT
	120	35x25	0.20	0.88	ELT2HM121R25KT
	150	30x30	0.20	1.00	ELT2HM151Q30KT
	150	30x35	0.20	1.04	ELT2HM151Q35KT
	150	35x30	0.20	1.04	ELT2HM151R30KT
	180	30x40	0.20	1.17	ELT2HM181Q40KT
	180	35x30	0.20	1.10	ELT2HM181R30KT
	220	25x50	0.20	1.21	ELT2HM221P50KT
	220	30x40	0.20	1.26	ELT2HM221Q40KT
	220	30x45	0.20	1.33	ELT2HM221Q45KT
	220	35x35	0.20	1.23	ELT2HM221R35KT
	270	30x50	0.20	1.50	ELT2HM271Q50KT
	270	35x40	0.20	1.42	ELT2HM271R40KT
	330	35x45	0.20	1.60	ELT2HM331R45KT
	330	35x50	0.20	1.64	ELT2HM331R50KT
	390	35x50	0.20	1.78	ELT2HM391R50KT
	470	35x60	0.20	2.03	ELT2HM471R60KT

※ Specifications subject to change without notice.

WV (V _{dc})	Cap (μF)	Size ΦDxL(mm)	tanδ	Rated ripple current (Arms/105°C, 120Hz)	Part Number
550	120	30x30	0.20	0.91	ELT2JM121Q30KT
	150	30x35	0.20	1.04	ELT2JM151Q35KT
	180	30x40	0.20	1.17	ELT2JM181R40KT
	180	35x30	0.20	1.10	ELT2JM181R30KT
	220	30x50	0.20	1.33	ELT2JM221Q50KT
	220	35x40	0.20	1.23	ELT2JM221R40KT
	270	35x45	0.20	1.42	ELT2JM271R45KT
	330	35x50	0.20	1.64	ELT2JM331R50KT
	390	35x55	0.20	1.85	ELT2JM391R55KT
	470	35x60	0.20	2.03	ELT2JM471R60KT