

Accessories

End Plate

DPDT2.5

Height : 23 mm

Width : 60 mm

Thickness : 2 mm



Barrier Plate

DBF - 3

Height : 50 mm

Width : 78 mm

Thickness : 3 mm



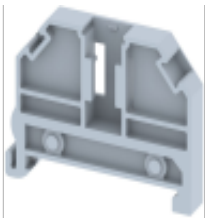
End Clamp

DCKN (Screwless - 35 mm Rail Mounted)

Height : 33 mm

Width : 43.50 mm

Thickness : 6 mm

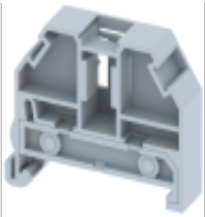


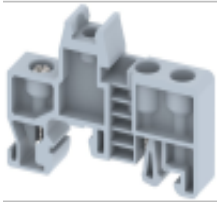
 
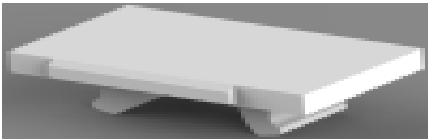
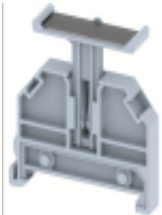
DCKN10 (Screwless - 35 mm Rail Mounted)

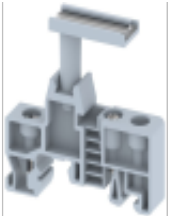
Height : 33 mm

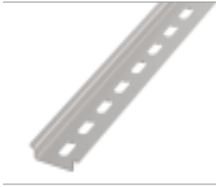
Width : 43.50 mm

Thickness : 10 mm



SCKN (35 mm Rail Mounted) Height : 35.50 mm Width : 50.60 mm Thickness : 8 mm	
SCUN (Universal Rail Mounted) Height : 35.50 mm Width : 50.60 mm Thickness : 9.50 mm	
Screwless Push-in type shorting link	
SSL 2.5 (2W)	
Marking Label	
LABEL KN5	
Group Marking Carrier	
DCKNMLH Height : 45.50 mm Width : 43.50 mm Thickness : 6 mm	

SCKNMLH Height : 45.50 mm Width : 48 mm Thickness : 8 mm	
SCUNMLH Height : 53.50 mm Width : 50.60 mm Thickness : 8 mm	
Mounting Channel (Standard Lengths 300 mm, 500 mm, 1000 mm)	
CHK Height : 7.5 mm Width : 35 mm Thickness : 1 mm	
CHKD Height : 15 mm Width : 35 mm Thickness : 1.50 mm	
CHKDS (Perforated) Height : 15 mm Width : 35 mm Thickness : 1.50 mm	

CHKS (Perforated) Height : 7.5 mm Width : 35 mm Thickness : 1 mm	
Group Marking Holder	
GMH 10 Height : 51 mm Width : 41.50 mm Thickness : 10 mm	
GMH 20 Height : 51 mm Width : 41.50 mm Thickness : 20 mm	
PVC Transparent Protection cover	
PCPDBF - 3 Height : 13 mm Width : 83 mm Thickness : 1 mm	

Note : Technical specifications may change in line with technical advances and industry standards