

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

1300061583

Status:

Active

Overview:

Brad Mini-Change Connectors

Description:


Mini-Change A-Size Single-Ended Cordset, 6 Poles, Female (Straight) to Pigtail, 16 AWG, Yellow PVC Cable, 1.83m (6.0') Length

Documents:

Drawing (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification	
CSA	LR6837
UL	E152210
General	
Product Family	Industrial Cordsets
Series	130006
Connector End A	Mini-Change
Connector End B	Pigtail
IP Rating	IP67
Material - Contact	Copper Alloy
Overview	Brad Mini-Change Connectors
Product Name	Mini-Change
Protocol	DeviceNet
Region	America
Taxonomy	Circular Industrial Cordsets
Type	Single Ended
UPC	78678843712
Physical	
Cable Diameter	13.72mm (.540")
Cable Length	1.83m (6.0')
Color - Cable Jacket	Yellow
Coupling Style	Threaded
Gender	Female-Pigtail
Keyway	Single
LED Indicator	No
Material - Cable Jacket	PVC
Material - Connector Body	TPE
Material - Coupling Nut	Black Epoxy Coated Zinc
Material - Plating Mating	Gold
Net Weight	99.000/g
Orientation	Straight to Pigtail
Poles	6
Temperature Range - Operating	-20° to +105°C
Wire Size AWG	16
Wire/Cable Type	STOOW
Electrical	
Current - Maximum per Contact	8.0A
Voltage - Maximum	600V
Material Info	
Engineering Number	106000A01F060
Reference - Drawing Numbers	
Sales Drawing	SD-130006-011-001

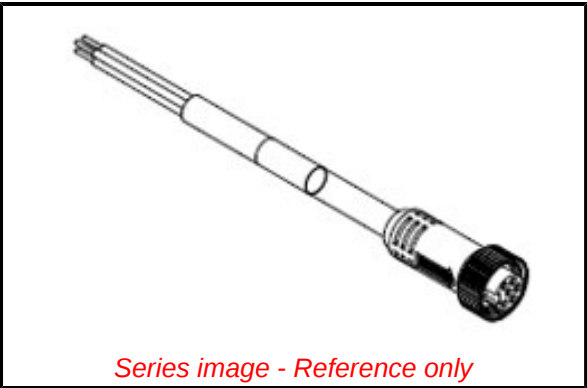

Series image - Reference only

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant with Exemption 6(c)	
REACH SVHC	
Not Reviewed	
Halogen-Free	
Status	
Not Reviewed	
For more information, please visit Contact US	
China ROHS	50 Image
ELV	Not Relevant
RoHS Phthalates	Not Contained
ZZCERT_CE - Declaration of Conformity	CER_4000408918_00_000.pdf
ZZCERT_UKCA - Declaration of Conformity	CER_4000410285_00_000.pdf

Search Parts in this Series

130006 Series

This document was generated on 09/15/2022

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION