

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

1200650471

Status:

Active

Overview:


Brad Micro-Change (M12) Connectors

Description:

Micro-Change (M12) Single-Ended Cordset, 5 Poles, Female (Straight) to Pigtail, 22 AWG, Yellow PVC Cable, 2.0m (6.56') Length

Documents:	
Drawing (PDF)	RoHS Certificate of Compliance (PDF)

Agency Certification	
CSA	LR6837
UL	E152210
General	
Product Family	Industrial Cordsets
Series	120065
Connector End A	Micro-Change (M12)
Connector End B	Pigtail
IP Rating	IP67
Material - Contact	Copper Alloy
Overview	Brad Micro-Change (M12) Connectors
Product Name	Micro-Change (M12)
Protocol	N/A
Region	America
Taxonomy	Circular Industrial Cordsets
Type	Single Ended
UPC	78678824907
Physical	
Cable Diameter	5.72mm (.225")
Cable Length	2.0m (6.56')
Color - Cable Jacket	Yellow
Coupling Style	Threaded
Gender	Female-Pigtail
Keyway	Single
LED Indicator	No
Material - Cable Jacket	PVC
Material - Connector Body	PUR
Material - Coupling Nut	Nickel-plated Brass
Material - O-Ring	Fluoro-elastomer
Material - Plating Mating	Gold
Net Weight	124.000/g
Orientation	Straight to Pigtail
Poles	5
Temperature Range - Operating	-20° to +105°C
Wire Size AWG	22
Wire/Cable Type	UL 2661
Electrical	
Current - Maximum per Contact	4.0A
Voltage - Maximum	250V AC/DC
Material Info	
Engineering Number	805000A09M020
Reference - Drawing Numbers	
Sales Drawing	SD-120065-026-001

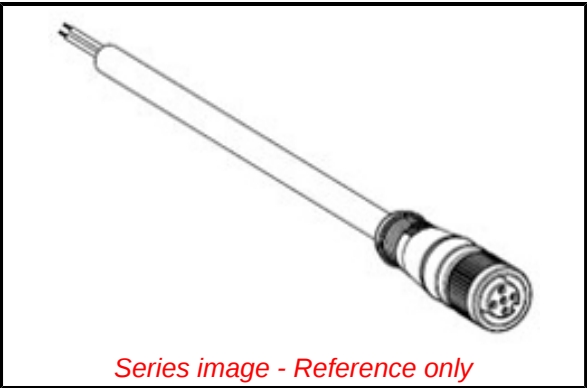

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant with Exemption 6(c)	
REACH SVHC	
Contained Per - D(2022)4187-DC (10 June 2022)	
Lead	
Halogen-Free	
Status	
Not Low-Halogen	
For more information, please visit Contact US	
China ROHS	Not Relevant
ELV	Not Relevant
RoHS Phthalates	Not Contained
ZZCERT_CE - Declaration of Conformity	CER_4000380980_00_000.pdf
ZZCERT_UKCA - Declaration of Conformity	CER_4000410293_00_000.pdf

Search Parts in this Series

120065 Series

This document was generated on 09/14/2022

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION