

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

1300150137

Status:


Active

Overview:

Brad Mini-Change Connectors

Description:

Mini-Change C-Size Receptacle, 9 Poles, 1/2" - 14 NPT Threads, Male (Straight) to 16 AWG Leads, 0.305m (1.0') Length

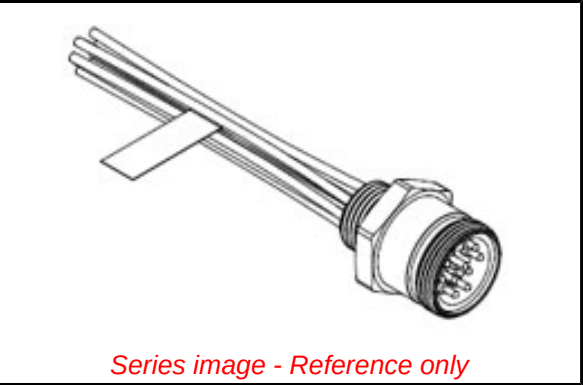

Documents:

Drawing (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification	
CSA	LR6837
UL	E152210
General	
Product Family	Industrial Receptacles
Series	130015
Comments	C-Size (1-1/8" - 16 UN-2A)
IP Rating	IP67
Overview	Brad Mini-Change Connectors
Product Name	Mini-Change
Taxonomy	Circular Industrial Connectors
Type	Single Ended (pigtail)
UPC	78678844209
Physical	
Coupling Type	External Thread
Gender	Male
Keyway	Single
Length	0.305m
Material - Component	Zinc Die-Cast with Black Epoxy
Mounting Thread Size	1/2" - 14 NPT
Net Weight	241.000/g
Orientation	Straight
Panel Mount	Front
Poles	9
Temperature Range - Operating	-20° to +105°C
Wire Size AWG	16
Wire/Cable Type	UL 1015
Electrical	
Current - Maximum per Contact	7.0A
Voltage - Maximum	600V AC/DC
Material Info	
Engineering Number	3R9006A20A120
Reference - Drawing Numbers	
Sales Drawing	SD-130015-003-001, SD-130015-027-001

EU ELV

Not Relevant

EU RoHS

Compliant with Exemption 6(c)

REACH SVHC

Contained Per - D(2022)4187-DC (10 June 2022)

Lead

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China RoHS

50 Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

ZZCERT_CE - Declaration of Conformity

CER_4000408918_00_000.pdf

ZZCERT_UKCA - Declaration of Conformity

CER_4000410292_00_000.pdf

Search Parts in this Series

130015 Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION