

Molex's range of pre-crimped leads offers a simple, cost-effective solution for prototyping, pre-production and mass production requirements. These leads are offered in female-to-female and male-to-male configurations in lengths of 75.00 to 600.00mm



C-Grid III



CLIK-Mate



DuraClik



iGrid



KK



LINK 250



LINK 396



Mega-Fit




MicroClasp




Micro-Fit 3.0



Micro-Lock Plus

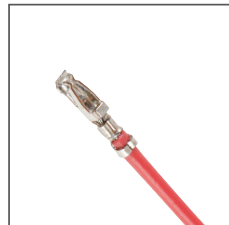

Micro-Lock Plus 2.0

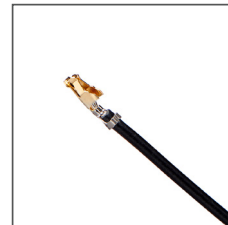

Milli-Grid



Mini-Fit



Mini-Fit Sigma



Mini-Fit Sr.




Mini-Lock



Mizu-P25



MLX

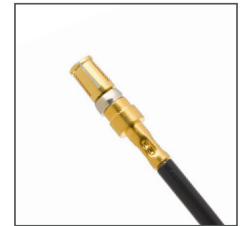


MultiCat



MX150



Nano-Fit

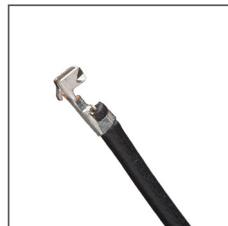

PicoBlade



Pico-Clasp



Pico-EZmate



Pico-Lock



Pico-SPOX



Sabre




Sherlock



SL



Solderless Ring

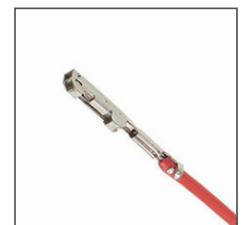

Squba 1.80mm



Squba 3.60mm



Standard .062"



Standard .093"



Ultra-Fit

Product Family	Series Number	Length (mm)	Connector A	Connector B	Wire Size (AWG)	Wire/Cable Type
C-Grid	79758	150, 300	Female	Female	22	UL 1061
CLIK-Mate	79758, 215710, 215711	75, 150, 225, 300, 450	Female, Male	Female, Male	24, 26, 28	UL 1061, UL 10002
DuraClik	79758	150, 300	Female	Female	26	UL 1061
iGrid	217490, 217491	75, 150, 225, 300, 450	Female	Female	22, 24, 26	UL 10002
KK	79758	150, 300	Female, Male	Female, Male	22, 24	UL 1061, UL 1007
L1NK 396	79758	150	Female	Female	18	UL 1051
Mega-Fit	79758	150, 300	Female	Female	16, 12	UL 1015
Micro-Clasp	79758	150, 300	Female	Female	24	UL 1007
Micro-Fit 3.0	79758, 214760, 214761, 214762, 214763	150, 300, 600	Female, Male	Female, Male, -	18, 20	UL 1061, UL10002
Micro-Lock Plus	79758	150, 300	Female	Female	26	UL 1061
Micro-Lock Plus 2.0	217500, 217501	75, 150, 225, 300, 450	Female	Female, Strip	22, 24, 26	UL 10002
Milli-Grid	79758	150, 300	Female	Female	24	UL 1061
Mini-Fit	79758, 215340, 215341, 215342, 215343	75, 150, 225, 300, 450	Female, Male	Female, Male	16, 18, 20	UL 1015, UL 1061
Mini-Fit Sigma	219670, 219671	75.00, 150.00, 225.00, 300.00, 450.00	Female	Female	16, 18, 20	UL 11028
Mini-Fit Sr.	217480, 217481, 217482, 217483	150, 225, 300, 450	Female, Male	Female, Male	8, 10, 12	UL 10669
Mini-Lock	79758	150, 300	Female	Female	22	UL 1061
Mizu-P25	217840, 217841, 217842, 217843, 217520, 217521, 217522, 217523	75, 150, 225, 300, 450,	Female, Male	Female, Male	20, 22	UL10002, FLRY-B
MLX	79758	150, 300	Female, Male	Female, Male	18	UL 1015
Multicat	79758	150, 300	Female, Male	Female, Male	8, 9, 12, 16	UL 1199

### Ordering Information

Product Family	Series Number	Length (mm)	Connector A	Connector B	Wire Size (AWG)	Wire/Cable Type
MX150	216300, 216301, 216302, 216303	150, 225, 300, 450, 600	Female, Male	Female, Male	14, 16, 18	TXL
Nano-Fit	79758	150, 300	Female	Female	20	UL 1061
PicoBlade	79758, 214920, 214921, 214922, 214923	75, 150, 225, 300, 450	Female, Male	Female, Male	26, 28	UL1061
Pico-Clasp	79758	150, 300	Female	Female	28	UL 1571
Pico-EZmate	79758	300	Female	Female	28	UL 1516
Pico-Lock	79758	150, 300	Female	Female	24, 30	UL 1061, UL 1571
Pico-SPOX	79758	150, 300	Female	Female	24	UL 1061
Sabre	79758	150, 300	Female, Male	Female, Male	16	UL 1015
Sherlock	79758	150, 300	Female	Female	26	UL 1061
SL	79758	150	Female	Female	22	UL 1061
Squba 1.80mm	217790, 217791, 217792, 217793	75, 150, 225, 300, 450	Female	Female	22, 24	UL 10002
Squba 3.60mm	215345, 215346, 215347, 215348	75, 150, 225, 300, 450	Female, Male	Female, Male	16, 18, 20	UL 11028
Standard .062"	79758	150, 300	Female, Male	Female, Male	22	UL 1015
Standard .093"	79758	150, 300	Female, Male	Female, Male	18	UL 1015

Product Family	Series Number	Length (mm)	Stud Size	Wire Termination	Wire Size (AWG)	Wire/Cable Type
Solderless Ring Terminal	217851	150	10 (M5)	Blunt cut	16 AWG	UL 1015
		300				
		600				

[www.molex.com/link/precrimped.html](http://www.molex.com/link/precrimped.html)