



Standard Quick Wire Thermocouple Connector Plug & Socket IS-K-MQ+FQ Type K IEC

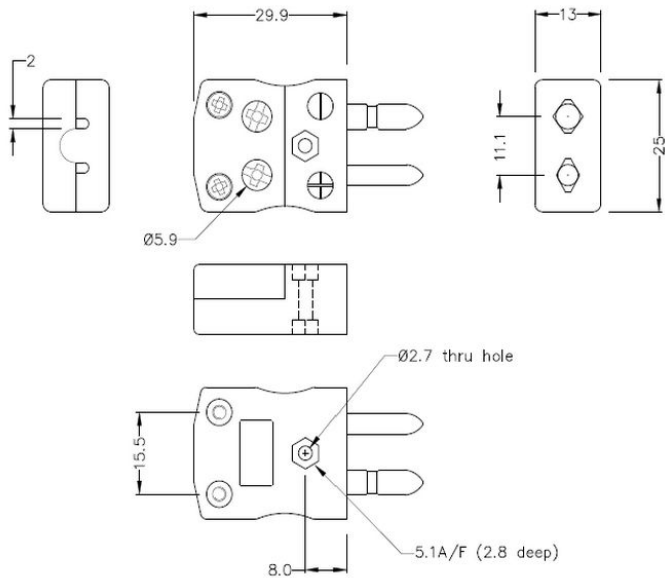

Standard in-line Plug - Quick Wire
(dimensions in mm)

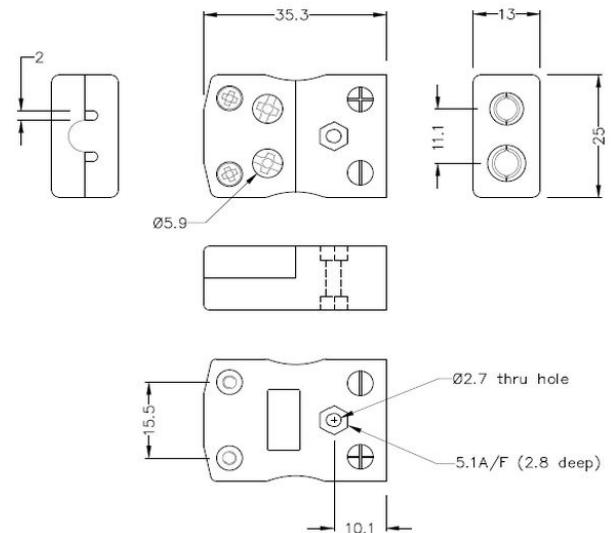

Standard in-line Socket - Quick Wire
(dimensions in mm)

Product Code	XF-1727-FAR
General Description	Easy 'jab-in' connection for rapid termination, contacts are polarised to prevent incorrect connection
Thermocouple Type	K IEC
Connector Size	Standard
Connector Type	Quick Wire Plug & Socket
Colour	Green
Max. Temperature	220°C
Pins	Solid Round Pins
+Positive Contact	Nickel Chromium

-Negative Contact	Nickel Alloy
Standards Met	BS EN 50212:1997. RoHS

