


# Standard Quick Wire Panel Mount Thermocouple Connector with Stainless Steel Bracket IS-K-SSPFQ Type K IEC

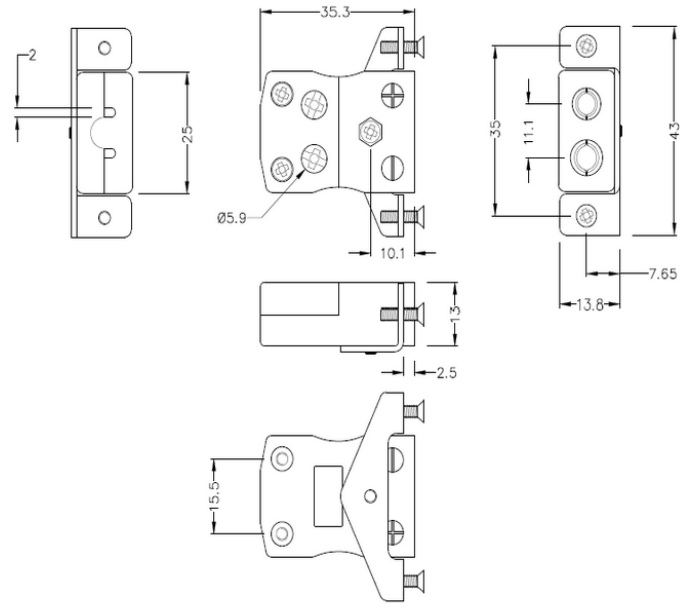

**Standard Socket - Quick Wire with stainless steel mounting bracket**  
(dimensions in mm)

<b>Product Code</b>	XF-1730-FAR
<b>General Description</b>	Easy 'jab-in' connection for rapid termination, just push wire in and tighten screw
<b>Thermocouple Type</b>	K IEC
<b>Connector Type</b>	Quick Wire Socket with SS Bracket
<b>Connector Size</b>	Standard
<b>Colour</b>	Green
<b>Max. Temperature</b>	220°C
<b>+Positive Contact</b>	Nickel Chromium
<b>-Negative Contact</b>	Nickel Alloy
<b>Standards Met</b>	BS EN 50212:1997. RoHS

