


Datasheet

Glassfibre + SSOB Thermocouple Cable 4 Core 7/0.2 Type K

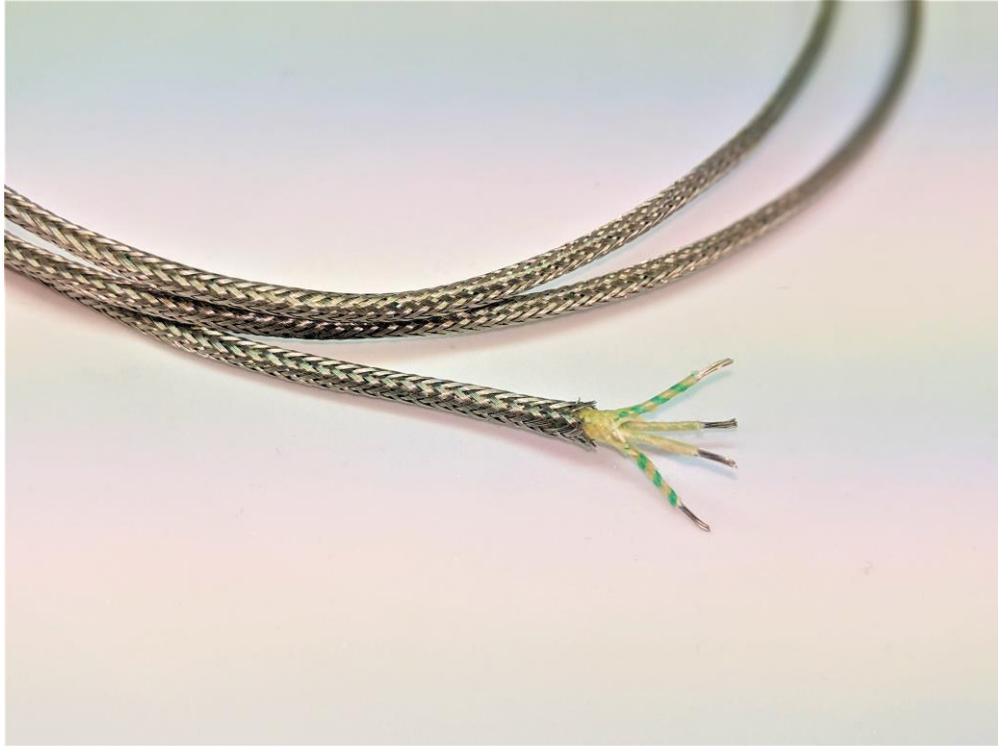

Glassfibre insulated flat pair construction, conductors laid flat, Glassfibre insulated with Glassfibre jacket, silicone varnished throughout + stainless steel overbraid for added protection and mechanical strength. Good temperature resistance but not suitable where fluids are present.

- Insulation Glassfibre insulated extension cable with stainless steel overbraiding
- Number of Cores 4
- Number of Strands 7
- Conductor Size (mm) 0.2
- Max. Temperature +350°C (short periods up to 400°C)
- Min. Temperature -60°C

Type	Length	Cores	Description	Manufacturers Code	Order Number
K	10m	4	7/0.2mm	WK-365-D	XF-1673-FAR
K	25m	4	7/0.2mm	WK-365-D	XF-1672-FAR
K	50m	4	7/0.2mm	WK-365-D	XF-1674-FAR
K	100m	4	7/0.2mm	WK-365-D	XF-1766-FAR