


Datasheet

IEC Glassfibre Flat Pair with Stainless Steel Overbraid Thermocouple Extension Cable (Type U)

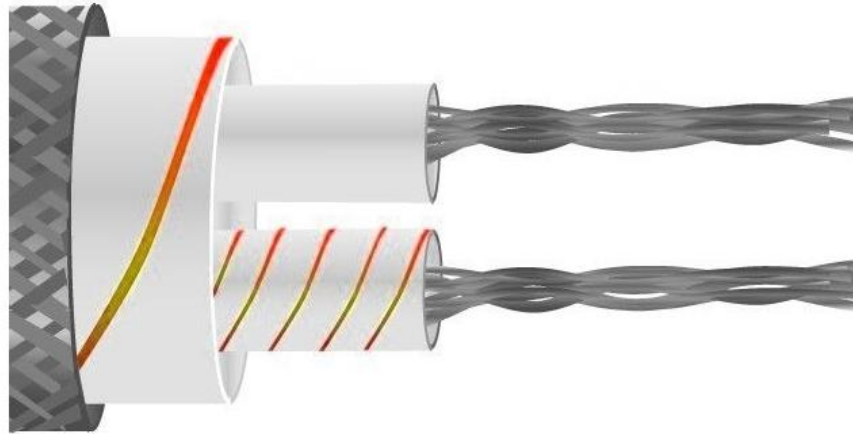

- Glassfibre insulated extension cable with stainless steel overbraiding
- 7/0.2mm stranded conductors
- Glassfibre insulated flat pair construction, conductors laid flat, Glassfibre insulated with Glassfibre jacket, silicone varnished throughout + stainless steel overbraid for added protection and mechanical strength
- Good temperature resistance but not suitable where fluids are present
- See below for available reel lengths
- Tolerance Class 2 to IEC-584
- Insulation rating -60°C to 350°C (short periods up to 400°C)
- Colour code (cores & jacket) to IEC-584-3

T/C Type	Conductors	Cores	Jacket	Reel Length	Manufacturers code	Order Code
RCA (U) 7/0.2mm		+Orange/-White	Orange	10 metres	WU-105-D	<b>XF-1714-FAR</b>
RCA (U) 7/0.2mm		+Orange/-White	Orange	25 metres	WU-105-D	<b>XF-1791-FAR</b>
RCA (U) 7/0.2mm		+Orange/-White	Orange	50 metres	WU-105-D	<b>XF-1813-FAR</b>
RCA (U) 7/0.2mm		+Orange/-White	Orange	100 metres	WU-105-D	<b>XF-1777-FAR</b>