



BS Glassfibre Exposed Welded Tip Thermocouples

About Labfacility


Formed in 1971, Labfacility specialize in the field of Temperature and Process Measurement.

We are the largest UK manufacturer of both temperature sensors and thermocouple connectors.

Quality & Service

Quality and Service are key elements in the continued growth of Labfacility.

Technical support is always freely available from our experienced technical sales teams and the company has ISO9001 accreditation.

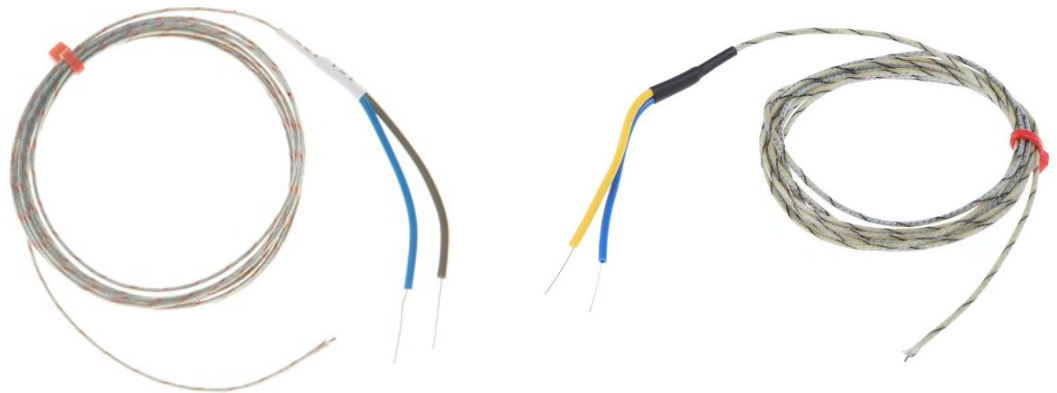

- Thermocouple type K, J
- Fast response, welded exposed junction
- 2-metre-long glassfibre insulated flat pair cable
- Good temperature resistance (not suitable in fluids)
- 1/0.3mm conductors
- Colour coded tail wires
- Temperature range -60°C to $+350^{\circ}\text{C}$ (short periods up to 400°C)
- Colour coded to former British Standard – BS1843-1952
- Tolerance in accordance with IEC 584 class 2
- Ideal for test & development applications

T/C Type	Conductors	Length	order code
'K'	1/0.3mm	2 m	XF-1199-FAR
'J'	1/0.3mm	2 m	XF-1835-FAR

Contact Details

Email
sales@labfacility.com

Website
www.labfacility.com