



Datasheet

BS Exposed Welded Tip Thermocouple – PTFE Insulated Cable

Type K & T, 1/0.2mm PTFE insulated twisted pair, 1-metre-long (Packs of 5)

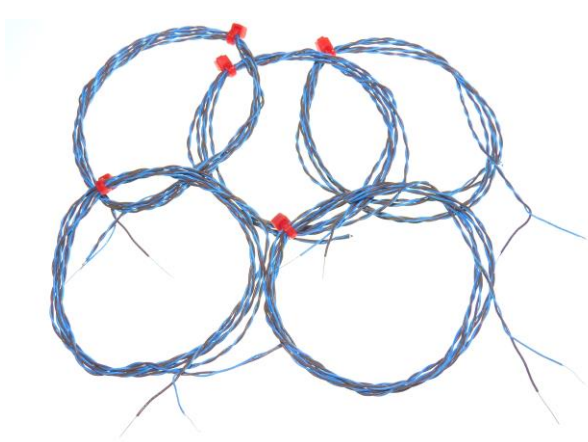

Type 'K'

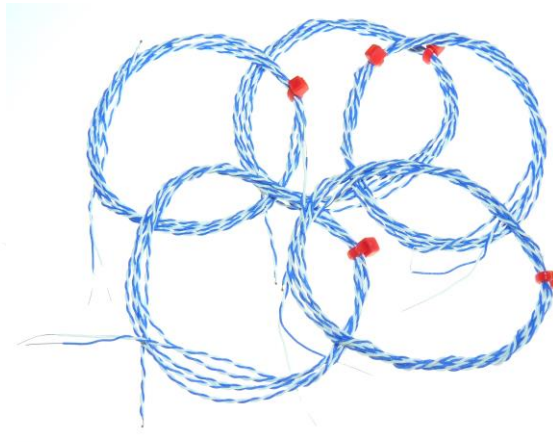

Type 'T'

- Exposed welded tip Thermocouple
- Fast response
- Type K or T
- 1/0.2mm PTFE insulated twisted wire
- 1 metre long
- Supplied in packs of 5
- Good mechanical strength and flexibility, resistant to oils, acids and other adverse fluids, steam, gasses etc.
- Ideal for test & development applications
- Temperature range -50°C to 250°C
- Colour coded to former British Standard – BS1843-1952
- Tolerance in accordance with IEC 584-2 specification (formerly BS4937:1983)

T/C Type	Conductors	mm ²	Length	Colour Code	No. Per Pack	order code
K	1/0.2mm	0.032	1 metre	+Brown/-Blue	x 5	XF-1832-FAR
T	1/0.2mm	0.032	1 metre	+White/-Blue	x 5	XF-1838-FAR