


Datasheet

# Adjustable Bayonet Thermocouple Type J IEC With Cable Clamps and Terminating in Standard Plug

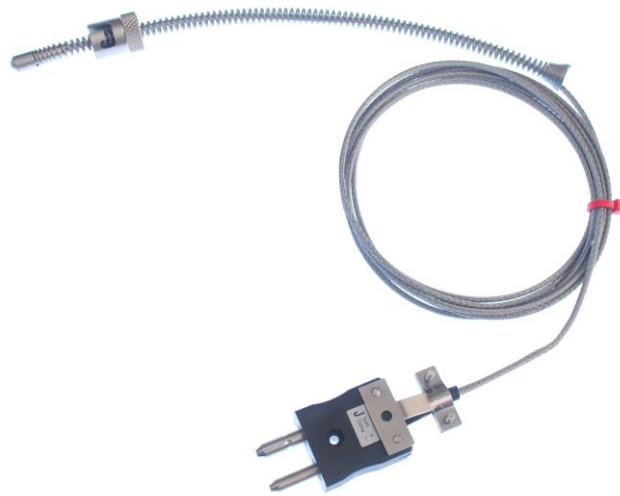

- Thermocouple with adjustable insertion depth
- 6.0mm diameter tip
- 200mm spring with adjustable fixing cap (11.5mm I.D. single slot)
- Glassfibre insulated lead with stainless steel overbraid, 7/0.2mm
- Rated 350°C
- Fitted with cable clamps and standard thermocouple plug
- Good temperature resistance but not suitable where fluids are present
- Tolerance Class 2 to IEC-584
- Insulation rating -60°C to 350°C (short periods up to 400°C)
- Colour code (cores & jacket) to IEC-584-3
- Type J available

| T/C Type | Conductors | Cores         | Length   | order code  |
|----------|------------|---------------|----------|-------------|
| J        | 7/0.2mm    | +Green/-White | 3 metres | XF-1959-FAR |