


Datasheet

Washer Thermocouple Type K or J IEC With Cable Clamps and Terminating in a Standard Plug

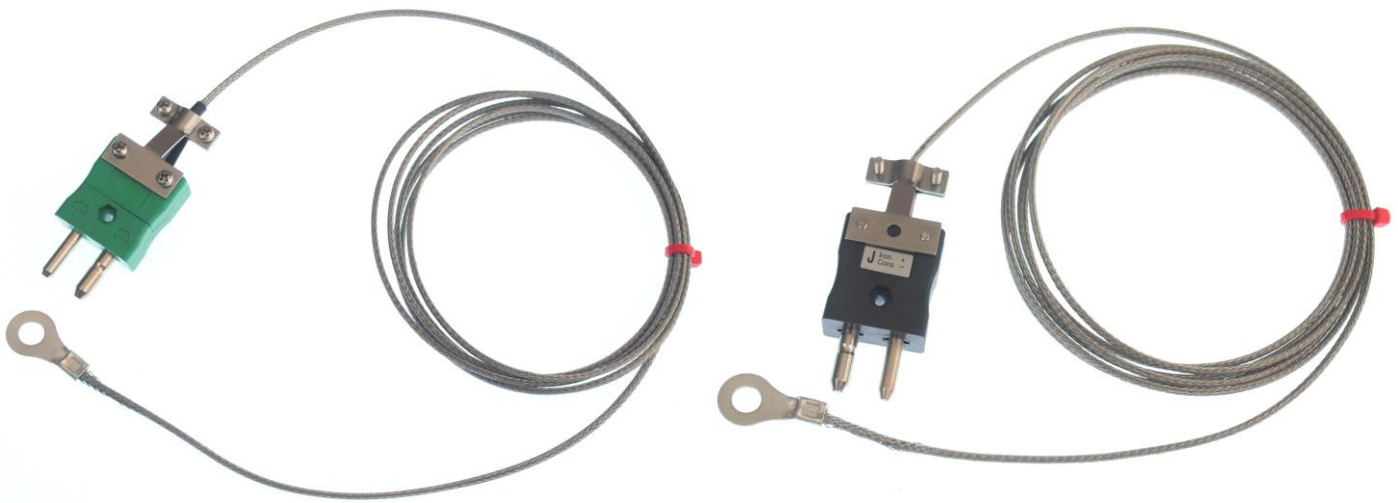

- Thermocouple housed in a washer eyelet
- Grounded tip for quick response
- Washer with 6mm clearance hole
- 2 Metre glassfibre insulated, stainless steel over braided extension lead, 7/0.2mm
- Glassfibre insulated flat pair construction, conductors laid flat, Glassfibre insulated with Glassfibre jacket, silicone varnished throughout + stainless steel overbraid for added protection and mechanical strength
- Fitted with cable clamps and standard thermocouple plug
- Good temperature resistance but not suitable where fluids are present
- Tolerance Class 2 to IEC-584
- Insulation rating -60°C to 350°C (short periods up to 400°C)
- Colour code (cores & jacket) to IEC-584-3

T/C Type	Conductors	Cores	Length	order code
K	7/0.2mm	+Green/-White	2 metres	XF-1961-FAR
J	7/0.2mm	+Black/-White	2 metres	XF-1962-FAR