




8142

**Ultra-Flush® Precision Cut
Diagonal Cutter with Oval Head &
ESD Safe Handle 0.1-1 mm**







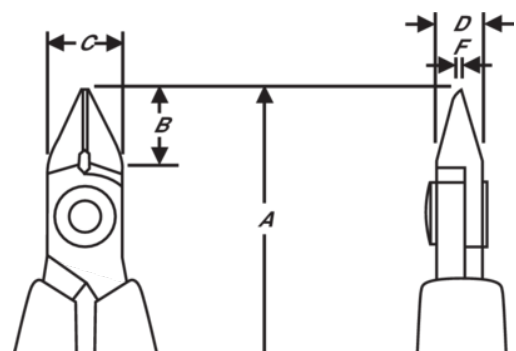



PRODUCT DETAILS

- 80 Series precision diagonal and stripping cutter
- ESD safe mono-material handles with return spring
- Micro-bevel cut
- The cutting capacity given is for copper wire
- Suitable for cutting Cu
- High performance alloyed steel
- Burnished finish
- Numerically controlled machine grinding guarantees edge angle accuracy & contact, increases the tools reliability & consistency
- Precision induction hardened edges 63-65 HRC
- Screw joint that minimizes friction & maximizes alignment of cutting edges
- Ideal for wire harness work & standard printed circuit board assembly
- Also valid for stripping



PRODUCT ATTRIBUTES

Product: **8142**

	Oval		S		Ultra-Flush ®
	0.1-1.0 mm		0.00-0.04 in		
		A	110 mm	A	4.33 in
B	10,5 mm	B	0,41 in	C	10 mm
C	0.39 in	D	6 mm	D	0,24 inch
F	0,8 mm	F	0,03 in		70 g
Ω	Dissipative				