




8130

**Micro-Bevel® Precision Cut
Diagonal Cutter with Oval Head &
ESD Safe Handle 0.2-1 mm**



PRODUCT DETAILS

- 80 Series precision diagonal and stripping cutter
- ESD safe mono-material handles with return spring
- Micro-bevel cut
- The cutting capacity given is for copper wire
- Suitable for cutting Cu
- High performance alloyed steel
- Burnished finish
- Numerically controlled machine grinding guarantees edge angle accuracy & contact, increases the tools reliability & consistency
- Precision induction hardened edges 63-65 HRC
- Screw joint that minimizes friction & maximizes alignment of cutting edges
- Ideal for wire harness work & standard printed circuit board assembly
- Also valid for stripping

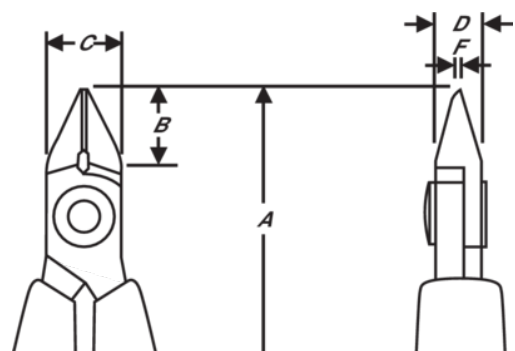

PRODUCT ATTRIBUTES

Product: **8130**

	Oval		XS		Micro-Bevel ®
	0.2-1.0 mm		0.01-0.04 in		
		A	108 mm	A	4.25 in
B	8,5 mm	B	0,33 in	C	8 mm
C	0.31 in	D	5 mm	D	0,2 inch
F	0,8 mm	F	0,03 in		68 g
Ω	Dissipative				