




8146

**Micro-Bevel® Precision Cut
Diagonal Cutter with Tapered &
Relieved Head & ESD Safe Handle
0.2-1 mm**



PRODUCT DETAILS

- 80 series precision diagonal cutters with tapered & relieved head
- ESD safe mono-material handles with return spring
- Micro-bevel, flush & ultra-flush cut
- The stated cutting capacity is for copper wire
- Suitable for cutting copper
- High performance alloy steel
- Burnished finish
- Numerically controlled machine grinding ensures edge angle accuracy and contact, increasing tool reliability and consistency
- Precision induction hardened edges 63-65 HRC
- Screw joint minimises friction and maximises alignment of cutting edges
- Ideal for use in confined spaces and for rework

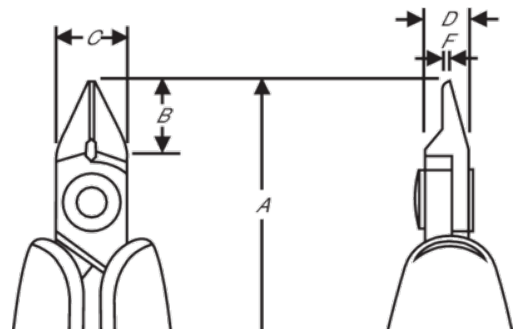

PRODUCT ATTRIBUTES

Product: **8146**

	Tapered & Relieved		S		Micro-Bevel ®
	0.2-1.0 mm		0.01-0.04 in	A	110.5 mm
A	4.33 in	B	10 mm	B	0,39 in
C	10 mm	C	0.39 in	D	6 mm
D	0,24 inch	F	0,8 mm	F	0,03 in
	46 g	Ω	Dissipative		