




 
7291

**Precision 11° Oblique End Head  
Cutters 0.35 mm-1.25 mm**







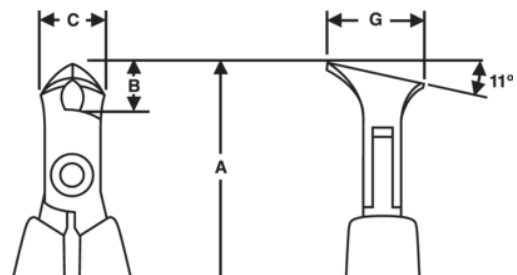

PRODUCT DETAILS

- Supreme series oblique cutter
- ESD safe mono-material handles with return spring
- Micro-bevel & flush cut
- The cutting capacity given is for copper wire
- Suitable for cutting Cu
- High performance alloyed steel
- Polished finish
- Numerically controlled machine grinding guarantees edge angle accuracy & contact, increases the tools reliability & consistency
- Precision induction hardened edges 58-60 HRC
- Screw joint that minimizes friction & maximizes alignment of cutting edges
- Angled shape ideal for use in confined spaces



PRODUCT ATTRIBUTES

Product: **7291**

	End		S		Flush
	0.35-0.8 mm		0.01-0.03 in	<b>A</b>	108 mm
<b>A</b>	4.25 in	<b>B</b>	8 mm	<b>B</b>	0,31 in
<b>C</b>	10,5 mm	<b>C</b>	0.41 in	<b>G</b>	15 mm
<b>G</b>	0,59 in		56 g	<b>Ω</b>	Dissipative