




7590-7591

## Round Nose Tipped Pliers with Synthetic Handle





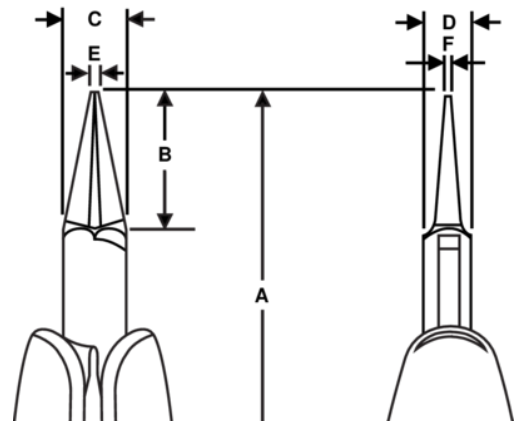

### PRODUCT DETAILS

- Supreme series round nose pliers
- Round jaws taper from 7 mm to 1.0 mm at the tip
- ESD safe mono-material handles with return spring
- High performance alloyed steel
- Polished finish
- Numerically controlled machine grinding guarantees accuracy & increases the tools reliability & consistency
- Tough hardened 42-46 HRC
- Screw joint that minimizes friction & maximizes jaw alignment
- Round jaws with no sharp edges
- 7591 with long tip







## PRODUCT ATTRIBUTES





### Product: 7590

	Round Nose		S	<b>A</b>	146.5 mm
<b>A</b>	5.77 in	<b>B</b>	20 mm	<b>B</b>	0,79 in
<b>C</b>	9 mm	<b>C</b>	0.35 in	<b>D</b>	6 mm
<b>D</b>	0,24 inch	<b>E</b>	1,4 mm	<b>E</b>	0,055 in
<b>F</b>	0,7 mm	<b>F</b>	0,027 in		Smooth
	69 g	<b>Ω</b>	Dissipative		

### Product: 7590 CO

	Round Nose		S	<b>A</b>	146.5 mm
<b>A</b>	5.77 in	<b>B</b>	20 mm	<b>B</b>	0,79 in
<b>C</b>	9 mm	<b>C</b>	0.35 in	<b>D</b>	6 mm
<b>D</b>	0,24 inch	<b>E</b>	1,4 mm	<b>E</b>	0,055 in
<b>F</b>	0,7 mm	<b>F</b>	0,027 in		Smooth
	54 g	<b>Ω</b>	Conductive		

### Product: 7591

	Round Nose		M	<b>A</b>	165 mm
<b>A</b>	6.5 in	<b>B</b>	38,5 mm	<b>B</b>	1,51 in
<b>C</b>	9 mm	<b>C</b>	0.35 in	<b>D</b>	6,7 mm
<b>D</b>	0,24 inch	<b>E</b>	1,4 mm	<b>E</b>	0,055 in
<b>F</b>	0,7 mm	<b>F</b>	0,027 in		Smooth
	75 g	<b>Ω</b>	Dissipative		