

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1201088354](#)
Status: **Active**
Overview: Brad Industrial Ethernet Solutions
Description: Double-Ended RJ-45 Cordset, 4 Poles, Male (Straight) to Male (Straight), 22 AWG, Green Shielded TPE Cable, 2.0m (6.56') Length, 6.70mm (.264") Diameter

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

UL E200650

General

Product Family	Industrial Cordsets
Series	120108
Connector End A	RJ-45 (standard)
Connector End B	RJ-45 (standard)
IP Rating	IP20
Material - Contact	Phosphor Bronze
Overview	Brad Industrial Ethernet Solutions
Performance Category	5e
Product Name	Industrial Ethernet
Region	America, Asia, Europe
Taxonomy	Circular Industrial Cordsets
Type	Double Ended
UPC	889056150996

Physical

Cable Diameter	6.70mm (.264")
Cable Length	2.0m (6.56')
Color - Cable Jacket	Green
Coupling Style	Push and Latch
Gender	Male-Male
Keyway	N/A
LED Indicator	No
Material - Cable Jacket	TPE
Material - Connector Body	TPU
Material - Coupling Nut	N/A
Material - Plating Mating	Gold
Net Weight	167.362/g
Orientation	Straight to Straight
Poles	4
Temperature Range - Operating	-40° to +80°C
Wire Size AWG	22
Wire/Cable Type	Shielded TPE/AWM 21215

Electrical


Current - Maximum per Contact	1.5A
Voltage - Maximum	30V

Material Info

Engineering Number E66A06012M020

Reference - Drawing Numbers

Sales Drawing 1201088293-000

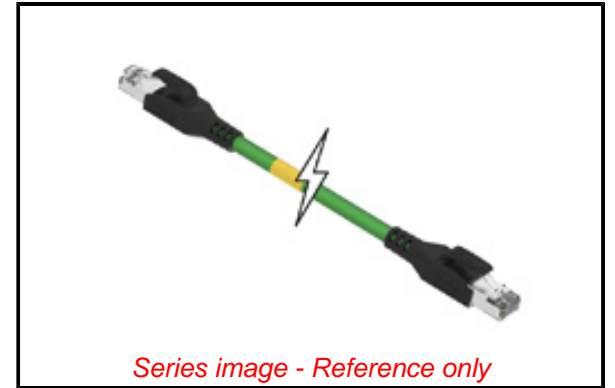

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

Search Parts in this Series

[120108 Series](#)

This document was generated on 08/29/2022

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION