

# ARCA 404021 No MP



Sample image

**Order symbol :** ARCA 404021 No MP

**Product nr :** 8120009N

**Description :** Cabinet, PC




**Remarks :** Grey cover, 2-point locking, hinges on the long side

**EAN :** 6418074086679

**El. number :**



- Finland :
- Denmark :
- Sweden : 2506468

**Including :** Cabinet base, door with PUR gasket, 3mm double bit lock(s) with key. S versions with swinghandle 2-point locking system. Door guide included.

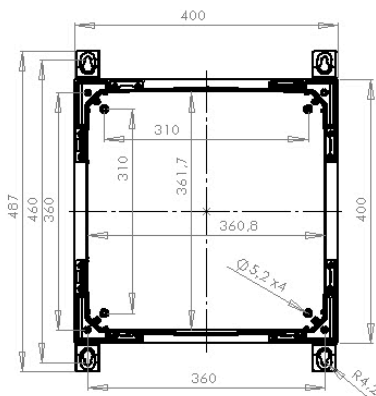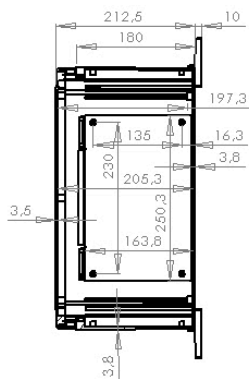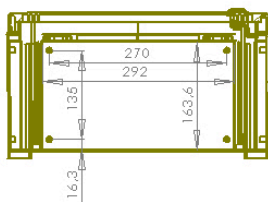

ARCA IEC DRS

ARCA IEC IDS

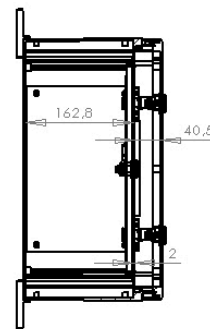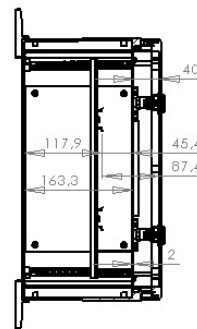

**Dimensions :**

	Height	Width	Depth
mm :	400	400	210
inch :	15.75	15.75	8.58

**Materials :**

Material :	Polycarbonate
Base colour :	RAL 7035 -light grey
Cover colour :	RAL 7035 -light grey
Gasket material :	Polyurethane

**Temperatures :**

Temperature °C (short term) :	-40 ... 120
Temperature °C (continuous) :	-40 ... 80
Temperature °F (short term) :	-40 ... 250
Temperature °F (continuous) :	-40 ... 175

**Accessories :**

IDS ARCA 4040	Inner door set (380 x 380 x 30)
MPX ARCA 4040	Mounting plate (350x350 mm) (350 x 350 x 5)
MPMP ARCA 4040	Mounting plate multiperforated (350x350x2 mm - ø3.6 mm) (350 x 350 x 2)
DRS ARCA 404021	DIN rail frame set (385 x 385 x35)
MPS ARCA 4040	Mounting plate (350x250x2 mm) (350 x 350 x 2)
MPP ARCA 4040	Mounting plate perforated (350x350x2 mm - 26x11 mm) (350 x 350 x 2)

**Rating :**

Ingress protection (EN 60529):	IP66;
Impact Resistance (EN 62262):	IK10;
Electrical insulation :	Totally insulated
Halogen free (DIN/VDE 0472, Part 815):	1
UV resistance :	UL 508
Flammability Rating :	UL 94 5VA

Glow Wire Test (IEC 695-2-1) °C : 960 °C

NEMA Class

NEMA 1, 4, 4X, 12 and  
13

**Certificates :**

Certificate FI 40467