

# ARCA 404021W



Sample image

**Order symbol :** ARCA 404021W

**Product nr :** 8120129

**Description :** Cabinet, PC


**Remarks :** Grey cover with window. 2-point locking.

**EAN :** 6418074079985

**El. number :**





- Finland :
- Denmark :
- Sweden : 2506477

**Including :** Cabinet base. door with PUR gasket. mounting plate. screws for mounting plate. 3mm double bit lock(s) with key. S versions with swinghandle 2-point locking system. Door guide included.

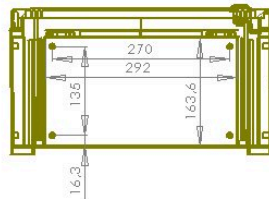

ARCA IEC DRS

ARCA IEC IDS

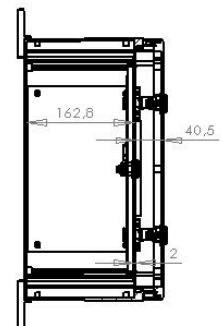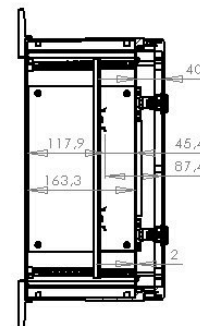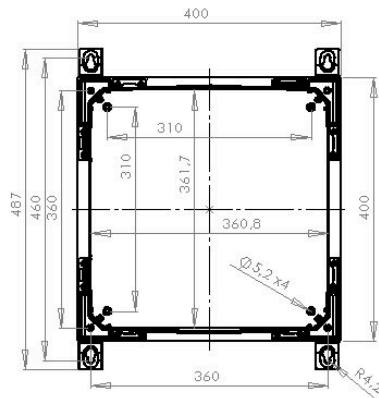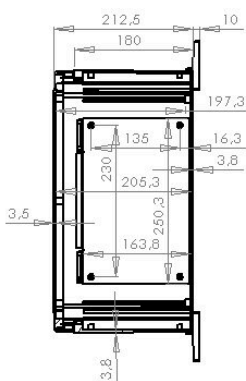

<b>Dimensions :</b>	<b>Height</b>	<b>Width</b>	<b>Depth</b>
mm :	400	400	210
inch :	15.75	15.75	8.58

#### **Materials :**

Material :	Polycarbonate
Base colour :	RAL 7035 -light grey
Cover colour :	Clear transparent
Gasket material :	Polyurethane

#### **Temperatures :**

Temperature °C (short term) :	-40 ... 120
Temperature °C (continuous) :	-40 ... 80
Temperature °F (short term) :	-40 ... 250
Temperature °F (continuous) :	-40 ... 175

#### **Accessories :**

IDS ARCA 4040	Inner door set (380 x 380 x 30)
MPX ARCA 4040	Mounting plate (350x350 mm) (350 x 350 x 5)
MPMP ARCA 4040	Mounting plate multiperforated (350x350x2 mm - ø3.6 mm) (350 x 350 x 2)
DRS ARCA 404021	DIN rail frame set (385 x 385 x35)
MPS ARCA 4040	Mounting plate (350x250x2 mm) (350 x 350 x 2)
MPP ARCA 4040	Mounting plate perforated (350x350x2 mm - 26x11 mm) (350 x 350 x 2)

#### **Rating :**

Ingress protection (EN 60529):	IP65;
Impact Resistance (EN 62262):	IK08;
Electrical insulation :	Totally insulated
Halogen free (DIN/VDE 0472, Part 815):	1
UV resistance :	UL 508
Flammability Rating :	UL 94 5VA
Glow Wire Test (IEC 695-2-1) °C :	960 °C
NEMA Class	

#### **Certificates :**

Certificate FI 40467