

ARCA 303021W No MP



Sample image

Order symbol : ARCA 303021W No MP

Product nr : 8120125N

Description : Cabinet, PC


Remarks : Grey cover, Swinghandle, hinges on the long side

EAN : 6418074087232

El. number :


- Finland :
- Denmark :
- Sweden : 2506476

Including : Cabinet base. door with PUR gasket. 3mm double bit lock(s) with key. S versions with swinghandle 2-point locking system. Door guide included.

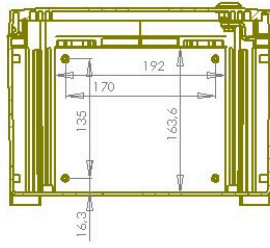

ARCA IEC DRS

ARCA IEC IDS

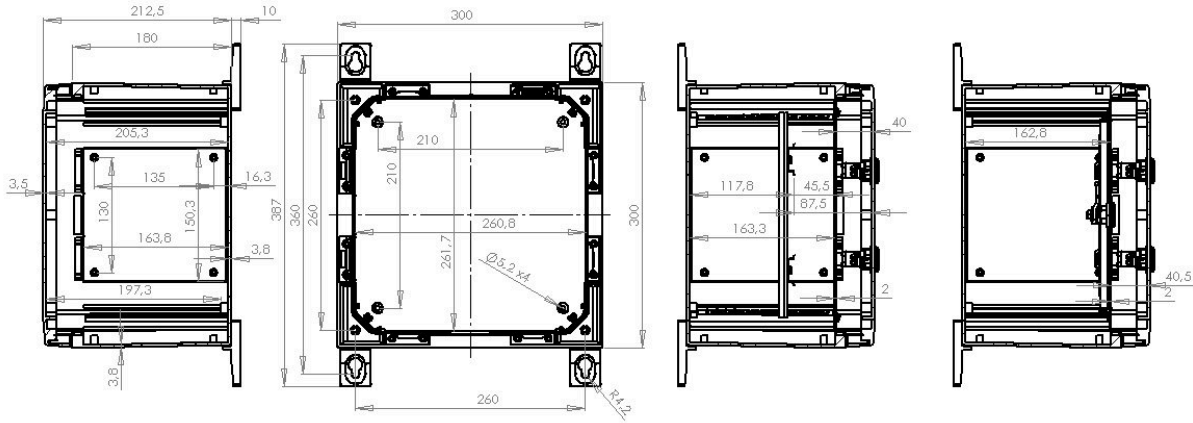

Dimensions :

	Height	Width	Depth
mm :	300	300	210
inch :	11.81	11.81	8.58

Materials :

Material :	Polycarbonate
Base colour :	RAL 7035 -light grey
Cover colour :	Clear transparent
Gasket material :	Polyurethane

Temperatures :

Temperature °C (short term) :	-40 ... 120
Temperature °C (continuous) :	-40 ... 80
Temperature °F (short term) :	-40 ... 250
Temperature °F (continuous) :	-40 ... 175

Accessories :

MPX ARCA 3030	Mounting plate (250x250 mm) (250 x 250 x 5)
MPMP ARCA 3030	Mounting plate multiperforated (250x250x2 mm - ø3.6 mm) (250 x 250 x 2)
MPS ARCA 3030	Mounting plate (250x250x2 mm) (250 x 250 x 2)
IDS ARCA 3030	Inner door set (280 x 280 x 30)
MPP ARCA 3030	Mounting plate perforated (250x250x2 mm - 26x11 mm) (250 x 250 x 2)
DRS ARCA 303021	DIN rail frame set (285 x 285 x35)

Rating :

Ingress protection (EN 60529):	IP65;
Impact Resistance (EN 62262):	IK08;
Electrical insulation :	Totally insulated
Halogen free (DIN/VDE 0472, Part 815):	1
UV resistance :	UL 508
Flammability Rating :	UL 94 5VA
Glow Wire Test (IEC 695-2-1) °C :	960 °C

NEMA Class

NEMA 1, 4, 4X, 12 and
13

Certificates :

Certificate FI 40467