

# ARCA 505021S No MP



Sample image

**Order symbol :** ARCA 505021S No MP

**Product nr :** 8120112N

**Description :** Cabinet, PC


**Remarks :** Grey cover, Swinghandle, hinges on the long side

**EAN :** 6418074314673

**El. number :**





- Finland :
- Denmark :
- Sweden : 2506480

**Including :** Cabinet base. door with PUR gasket. 3mm double bit lock(s) with key. S versions with swinghandle 2-point locking system. Door guide included.

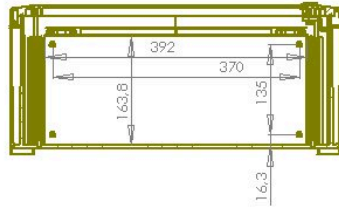

ARCA IEC DRS

ARCA IEC IDS

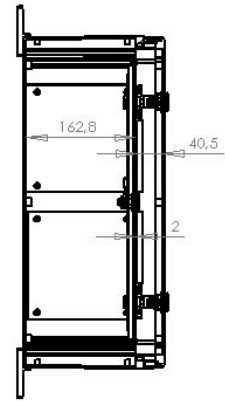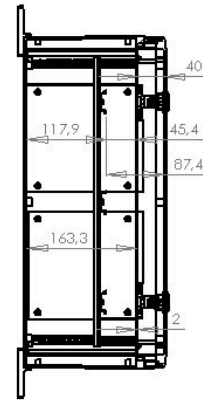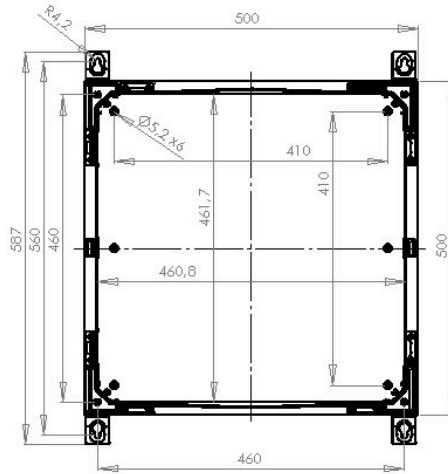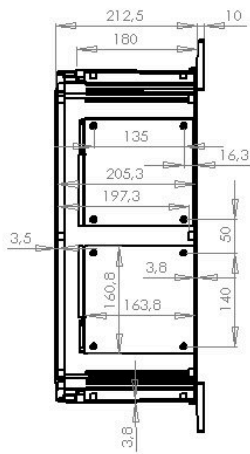

Dimensions :	Height	Width	Depth
mm :	500	500	210
inch :	19.69	19.69	8.27

**Materials :**

Material :	Polycarbonate
Base colour :	RAL 7035 -light grey
Cover colour :	RAL 7035 -light grey
Gasket material :	Polyurethane

**Temperatures :**

Temperature °C (short term) :	-40 ... 120
Temperature °C (continuous) :	-40 ... 80
Temperature °F (short term) :	-40 ... 250
Temperature °F (continuous) :	-40 ... 175

**Accessories :**

MPMP ARCA 5050	Mounting plate multiperforated (450x450x2 mm - ø3.6 mm) (450 x 450 x 2)
MPX ARCA 5050	Mounting plate (450x450 mm) (450 x 450 x 5)
MPS ARCA 5050	Mounting plate (450x450x2 mm) (450 x 450 x 2)
DRS ARCA 505021	DIN rail frame set (485 x 485 x35)
RCS ARCA 5050	Rain canopy set for size 5050 (20 x 500 x 30)
IDS ARCA 5050	Inner door set (480 x 480 x 30)
MPP ARCA 5050	Mounting plate perforated (450x450x2 mm - 26x11 mm) (450 x 450 x 2)

**Rating :**

Ingress protection (EN 60529):	IP66;
Impact Resistance (EN 62262):	IK10;
Electrical insulation :	Totally insulated

Halogen free (DIN/VDE 0472, Part 815):	1
UV resistance :	UL 508
Flammability Rating :	UL 94 5VA
Glow Wire Test (IEC 695-2-1) °C :	960 °C
NEMA Class	NEMA 1, 4, 4X, 12 and 13

**Certificates :**

Certificate FI 40467