


Series TC 44 25C

**Panel Mount 1 Row Barrier Terminal Block with
Solder Tag & Cover**

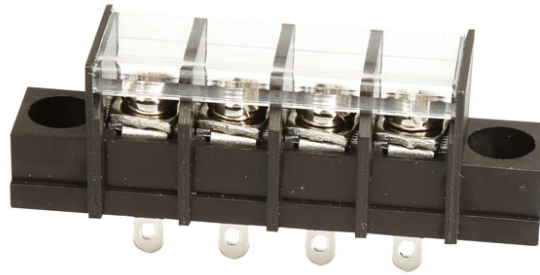

4 Ways shown, various available

Housing	PA66, UL94V-0
Screws	M4.0 Steel Nickel plated
Terminals	Copper alloy, Tin plated
Temperature Range	-40°C ~ +105°C
Standard	CE (BS EN 60998)
Current Rating	20 A
Voltage Rating	300 V
Withstanding Voltage	AC 2000V / 1 Min
Insulation Resistance	500 MΩ / DC 100V
Contact Resistance	20 mΩ
Wire Range	22-12AWG
Torque	1.2Nm

See Product Page for Diagram & Dimensions :

www.thermodatacomponents.co.uk/1rowbarrier