

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

1200110013

Status:


Active

Overview:

Brad Micro-Change (M12) Connectors

Description:

Micro-Change (M12) Receptacle, 4 Poles, M12x1 Threads, Female (Straight) to Leads, 0.30m (11.81") Length, Front Panel Mount

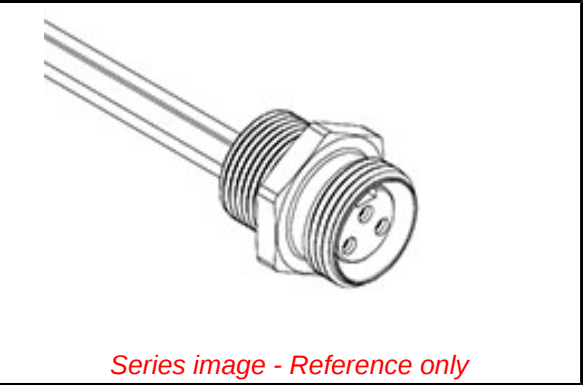

Series image - Reference only

Documents:

Drawing (PDF)

RoHS Certificate of Compliance (PDF)

General	
Product Family	Industrial Receptacles
Series	120011
IP Rating	IP67
NEMA Rating	NEMA 6
Overview	Brad Micro-Change (M12) Connectors
Product Name	Micro-Change (M12)
Taxonomy	Circular Industrial Connectors
Type	Single Ended (pigtail)
UPC	883906174941
Physical	
Coupling Type	Internal Thread
Gender	Female
Keyway	Single
Length	0.30m
Material - Component	Nickel-plated Brass
Mounting Thread Size	M14 x 1.0
Net Weight	25.960/g
Orientation	Straight
Panel Mount	Front
Poles	4
Temperature Range - Operating	-20° to +80°C
Wire Size AWG	22
Wire/Cable Type	Leads, UL 1061
Electrical	
Current - Maximum per Contact	4.0A
Voltage - Maximum	250V AC/DC
Material Info	
Engineering Number	8R4E30E03C3003

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant with Exemption 6(a)-I,6(c)	
REACH SVHC	
Contained Per - D(2022)4187-DC (10 June 2022)	
Lead	
Halogen-Free	
Status	
Not Low-Halogen	
For more information, please visit Contact US	
China ROHS	50 Image
ELV	Not Relevant
RoHS Phthalates	Not Contained
ZZCERT_CE - Declaration of Conformity	CER_4000406200_00_000.pdf
ZZCERT_UKCA - Declaration of Conformity	CER_4000410285_00_000.pdf

Search Parts in this Series

120011 Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION