


Coaxial PCB Connector 83_CT-0-2-1/-11_N

Description

Straight PCB cable terminator

Interface Standards

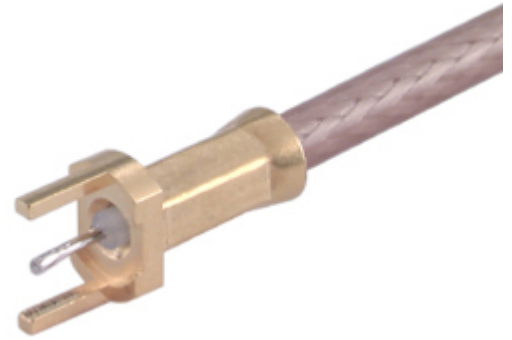

Technical Data

Electrical Data

Impedance other Ω

Mechanical Data

Board mounting type through holes
Weight 0.0007 kg

Environmental Data

Operating temperature -65 °C to 165 °C
2011/65/EU (RoHS - including
2015/863 and 2017/2102) compliant

Material Data

Piece Parts	Material	Surface Plating
Centre contact		
Outer contact	Brass	SUCOPRO Plating
Body	Brass	SUCOPRO Plating

Related Documents

Outline drawing DOU-00012683
Catalogue drawing DCA-00012685
Assembly instruction DOC-0000192778
Mounting hole DOU-00012682

Ordering Information

Single package 83_CT-0-2-1/-11_NE

Remarks

PCB connector with stand-offs, suitable for cable group U2 (RG_316_/U), cable entry: crimped