


## Coaxial PCB Connector 82\_MMBX-S50-0-13/111\_N

### Description

Straight PCB jack

Interface Standards  
SUHNER-MMBX

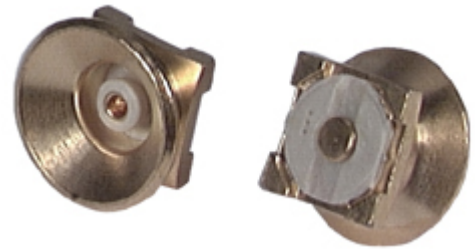

### Technical Data

#### Electrical Data

Impedance	50 $\Omega$
Interface frequency max.	12.4 GHz

#### Mechanical Data

Board mounting type	surface mount
Weight	0.0008 kg

#### Environmental Data

Operating temperature	-55 °C to 155 °C
2011/65/EU (RoHS - including 2015/863 and 2017/2102)	compliant

#### Material Data

Piece Parts	Material	Surface Plating
Centre contact	Brass	SUCOPRO Plating
Outer contact	Brass	SUCOPRO Plating
Body	Brass	SUCOPRO Plating
Insulator	LCP (Liquid crystal polymer)	

### Related Documents

Outline drawing	DOU-00001894
Catalogue drawing	DCA-00087583
Mounting hole	DOU-00012611

### Ordering Information

Bulk 100 pcs package	82_MMBX-S50-0-13/111_NH
Tape and Reel package	82_MMBX-S50-0-13/111_NM
Single package	82_MMBX-S50-0-13/111_NE

### Remarks

PCB connector with stand-offs