

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1731070163](#)
Status: **Active**
Overview: [FCT D-Sub Connectors](#)
Description: FCT Mixed Layout D-Sub Housing, Female, Tin-plated Shell without Dimples, Polarized, 4-40 UNC Clinch Nut, 2 Circuits

Documents:

[Datasheet \(PDF\)](#)
[Brochure \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

General


Product Family	D-Sub Products
Series	173107
IP Rating	IP20
Overview	FCT D-Sub Connectors
Product Category	D-Sub Connector
Product Name	FCT Products
Taxonomy	D-Sub Connectors
Type	Mixed Layout
UPC	889056485395

Physical

Circuits (Loaded)	0
Circuits (maximum)	2
Color - Resin	Black
Gender	Female
Material - Resin	PBT
Material - Shell	Steel
Net Weight	4.900/g
Number of Rows	1
PCB Locator	No
PCB Retention	None
Packaging Type	Carton
Panel Mount	Rear
Panel Mount Method	Thread-In
Plating - Shell	Tin
Polarized to Mating Part	Yes
Ports	1
Shielded	Yes
Temperature Range - Operating	-55° to +130°C
Waterproof / Dustproof	No
Waterproof / Dustproof Type	IP20

Material Info

Engineering Number FT2W2SC-K121

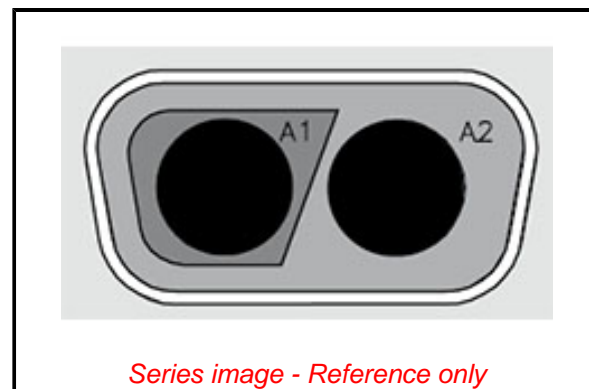

EU ELV

Not Relevant

EU RoHS

Compliant with Exemption 6(a)-I

REACH SVHC

Contained Per -
D(2021)10043-DC (17
Jan 2022)

Lead

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

50 Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

[173107 Series](#)

Mates With

FCT Mixed Layout D-Sub, Size 1, 2W2PC, Plug

Use With

FCT Coaxial, High Power, High Voltage, or Pneumatic Contacts