


PRIMO RANGE FLET PLIERS

NF E 73-102 / ISO 5745 / DIN ISO 5745

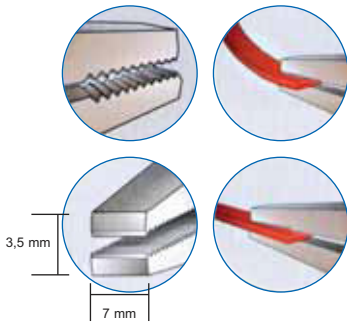


- Ribbed nose for better part gripping.
- Nose length: 46 mm.
- Orange PVC sleeve with guards.

L1	1	*	O	W	7 g
160	117250	9	3	-	137
160	117255	4	1	C2	157

PRIMO RANGE ROUND PLIERS

NF E 73-102 / ISO 5745 / DIN ISO 5745

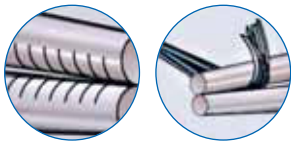


- Ribbed noses for better part gripping.
- Nose length: 41 mm.
- Nose diameter: 2 mm.
- Orange PVC sleeve with guards.

L1	1	*	O	W	7 g
167	117270	7	3	-	107
167	117275	2	1	C2	127

PRIMO RANGE HALF ROUND PLIERS


NF E 73-102 / ISO 5745 / DIN ISO 5745

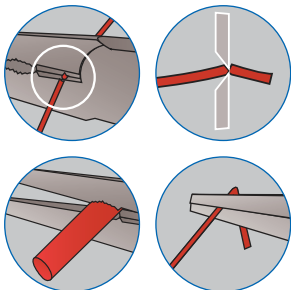

Long nose half round pliers

- Ribbed nose.
- Double induction treatment of cutting edges to cut semi-hard wires max 160 kg/mm²
- Orange PVC sleeve with guards.

L1	1	*	O	W	7 g
200	117330	8	3	-	165
200	117335	3	1	C2	185

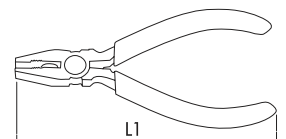

* For a full EAN, add the following before the code: 303254