

GP Batteries

Data Sheet

Model No.: GP24G

NO MERCURY ADDED

Description : Mercury Free Extra Heavy Duty Battery,
AAA Size

Chemical System : Zinc Chloride

Nominal Voltage : 1.5 Volts

Nominal Dimensions : $\varnothing 10.5$ mm x 44.5 mm

Terminals : Protruded positive(+) and flat negative(-)
contacts

Jacket : Printed PVC shrink sleeve


Applications : All electronic devices, e.g. toys,
photographic equipment, data banks,
calculators, audio appliances, remote
controls, paging machines.

Warranty Period : 36 months

Average Weight : 9g

Typical Service Life:

Discharge Resistance	Discharge Condition	End Point Voltage	Service Life
15 Ohms	24 Hrs/ Day	0.9V	290 Mins
50 Ohms	24 Hrs/ Day	0.9V	21 Hrs

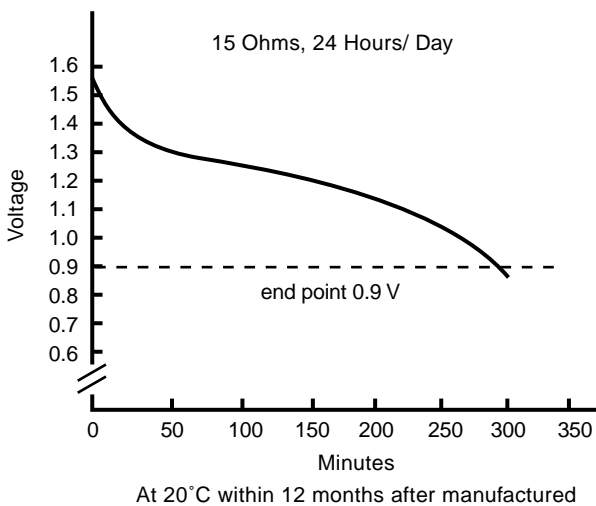

Cross References:

GP	JIS	IEC	Eveready
24G	R03	R03	1212

