



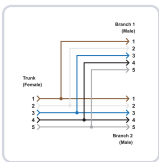

CSB-M1251FM1251M

► SPLITTERS

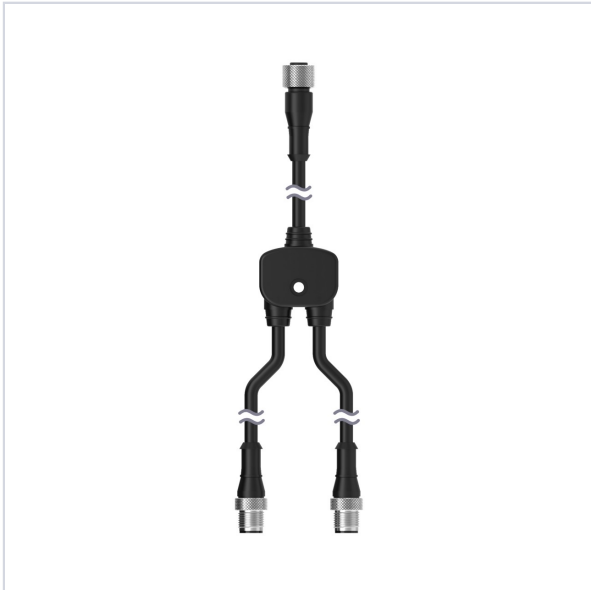

Splitter M12F to M12M and M12M connectors
5-pin, Non-Shielded, IP68, AWG 22
Black PVC Cord, Straight Connectors
Trunk: 0.3 m; Branches: 0.3 m
Part Number: 805287

SPECIFICATIONS

Trunk: Cable Jacket Material	PVC
------------------------------	-----

Branches: Orientations	Straight, Straight
Branches: Cable Jacket Material	PVC, PVC
Splitter: Overmold Material and Color	PUR Black
Wiring	Parallel
Branches: Number of Contacts	5, 5
Branches: Genders	Male, Male
Trunk: Connector Type	M12
Cookies	
By accepting cookies, we give you the best experience throughout our site, including access to My Account, My Library, and My Wish List.	
To learn more, visit our privacy policy .	
Branches: Connector Types	M12, M12
Number of Branches	2
Trunk: Orientation	Straight
Trunk: Gender	Female
Feature: Hazardous Area	No
Oil/Grease Resistant	No



Banner Engineering Corp. | 9714 Tenth Avenue North | Minneapolis, MN 55441 | United States of America

Cookies

By accepting cookies, we give you the best experience throughout our site, including access to My Account, My Library, and My Wish List.

To learn more, visit our [privacy policy](#).