

[Check Stock/Pricing by Product No.](#)[Search By Size and Type](#)[Find a Distributor / Rep](#)

[Home](#) / [Products](#) / [NEMA / IP Rated Boxes](#) / [NBB Series NEMA Box](#) / NEMA Box Poly PTB Blend NBB-15260

NEMA Box Poly PTB Blend NBB-15260



Model # NBB-15260

[NBB Series NEMA Box](#)

- For outdoor use.
- Clear door lets users read indicators and inspect for moisture without breaking seal.
- Designed to IP66 of IEC 529 and NEMA 1, 4 and 4x specifications.
- UL Listed to UL508-4x requirements.
- Gasketed plastic enclosure with latching lid is ideal for wet, washdown, dirty and corrosive environments.
- Opaque door

[Compare Sizes and Models](#)[See Accessories](#) [Request Modifications](#)[Check Stock / Pricing](#)

External Size L x W x D: 5.91" x 5.91" x 3.57"

Internal Size L x W x D: 5.04" x 5.04" x 3.27"

Weight: 1.2 lbs

Color: Light Gray

RoHS Certified: Always Compliant

Cover Style: Opaque, Hinged Cover

Indoor / Outdoor: Outdoor (UV Stabilized)

Flammability Rating: UL94-5VA

Door Flammability Rating: UL94-5A

Type of Plastic: Poly PBT Blend

Door Type of Plastic: Clear Polycarbonate

UL Rating: UL508



Gasket Type: Polyurethane

Service Temperature Min: -40°C

Service Temperature Max: 70°C


Latch Style: 2 Plastic Latches

NEMA Rating: NEMA 1, NEMA 4, NEMA 4X

IP Rating: 66



DRAWING

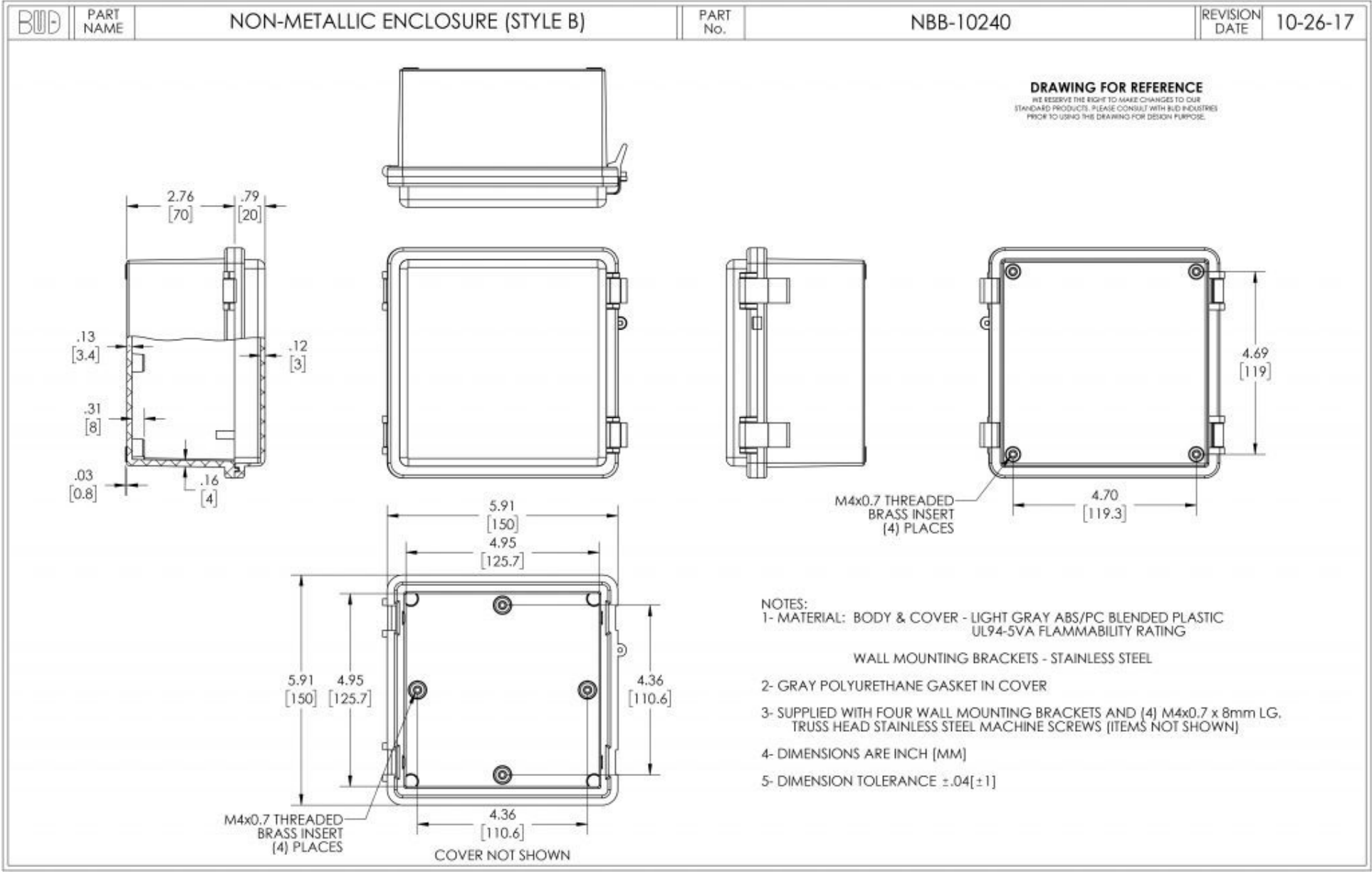

OTHER MODELS IN THIS SERIES

-- External Dimensions --

-- Internal Dimensions --

-- Cover Style --

-- Indoor / Outdoor --

-- Type of Plastic --

-- Door Type of Plastic --

Model #	External Dimensions	Internal Dimensions	Cover Style	Indoor / Outdoor	Type of Plastic
NBB-15260	5.91" x 5.91" x 3.57"	5.04" x 5.04" x 3.27"	Opaque, Hinged Cover	Outdoor (UV Stabilized)	Poly PBT Blend
NBB-15240	5.91" x 5.91" x 3.57"	5.04" x 5.04" x 3.27"	Opaque, Hinged Cover	Outdoor (UV Stabilized)	Poly PBT Blend
NBB-10260	5.91" x 5.91" x 3.57"	5.04" x 5.04" x 3.27"	Clear, Hinged Cover	Indoor (Not UV Stabilized)	ABS Poly Blend
NBB-10240	5.91" x 5.91" x 3.57"	5.04" x 5.04" x 3.27"	Opaque, Hinged Cover	Indoor (Not UV Stabilized)	ABS Poly Blend
NBB-22240	5.91" x 5.91" x 3.57"	5.04" x 5.04" x 3.27"	Opaque, Hinged Cover	Indoor (Not UV Stabilized)	ABS
NBB-10261	10.73" x 6.79" x 4.33"	9.84" x 5.90" x 4.07"	Clear, Hinged Cover	Indoor (Not UV Stabilized)	ABS Poly Blend
NBB-22241	10.73" x 6.79" x 4.33"	9.84" x 5.90" x 4.07"	Opaque, Hinged Cover	Indoor (Not UV Stabilized)	ABS
NBB-10241	10.73" x 6.79" x 4.33"	9.84" x 5.90" x 4.07"	Opaque, Hinged Cover	Indoor (Not UV Stabilized)	ABS Poly Blend
NBB-22243	11.28" x 7.48" x 5.51"	10.46" x 6.65" x 5.25"	Opaque, Hinged Cover	Indoor (Not UV Stabilized)	ABS

