

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

2196801222

Status:


Active

Overview:

Off-the-Shelf Pre-Crimped Leads

Description:

Pre-Crimped Lead SL Female-to-SL Female, Gold (Au) Plating, 150.00mm Length, 24 AWG, Black

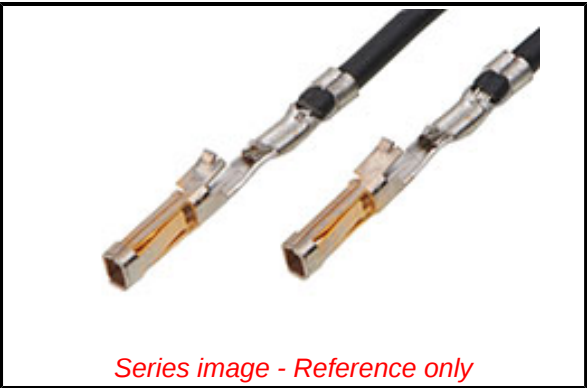

Documents:

[Drawing \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

[Datasheet \(PDF\)](#)

General	
Product Family	Cable Assemblies
Series	219680
Application	Signal, Wire-to-Board, Wire-to-Wire
Assembly Configuration	Pre-crimped Lead Only
Connector to Connector	SL Crimp Terminals
Overview	Off-the-Shelf Pre-Crimped Leads
Product Name	SL
Taxonomy	Power and Signal Cable Assembl
UPC	195842871724
Physical	
Cable Length	150.00mm
Circuits (Loaded)	1
Color - Resin	Black
Gender	Female-Female
Lock to Mating Part	Yes
Material - Metal	Phosphor Bronze
Material - Plating Mating	Gold
Material - Plating Termination	Tin
Net Weight	0.575/g
Number of Rows	1
Packaging Type	Bag
Plating min - Mating	0.380µm
Plating min - Termination	2.000µm
Single Ended	No
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	1.52mm max.
Wire Size AWG	24
Wire/Cable Type	UL 11028
Material Info	
Reference - Drawing Numbers	
Sales Drawing	2196801221-000

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per - D(2022)4187-DC (10 June 2022)	
Halogen-Free	
Status	
Low-Halogen	
For more information, please visit Contact US	
China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

219680 Series

Use With

SL Crimp Housing [70066](#) , [70450](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION