

CGA3E1C0G2A332J080AE

TDK item description : CGA3E1C0G2A332JT***S




Equivalent C1608C0G2A332J for Automotive

Application & Main Feature

Automotive grade (Soft termination)

Series

CGA3(1608) [EIA 0603]

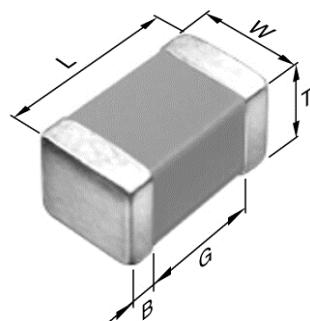

Dimensions

L 1.60+0.20/-0.10 mm
W 0.80+0.15/-0.10 mm
T 0.80+0.15/-0.10 mm
B 0.20 mm min.
G 0.30 mm min.

Temperature Characteristic

C0G (-55 to +125 degC, 0±30ppm/°C)

Rated Voltage

2A (100Vdc)

Capacitance

3.3nF

Capacitance Tolerance

J (±5%)

Q






1000 min.

Insulation Resistance

10000 Mohm min.

AEC-Q200

Yes

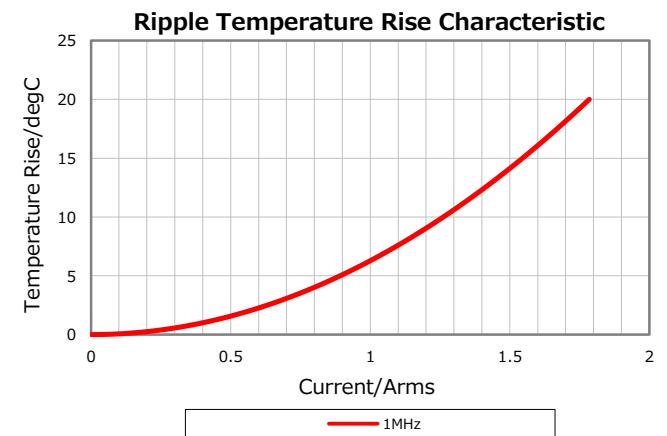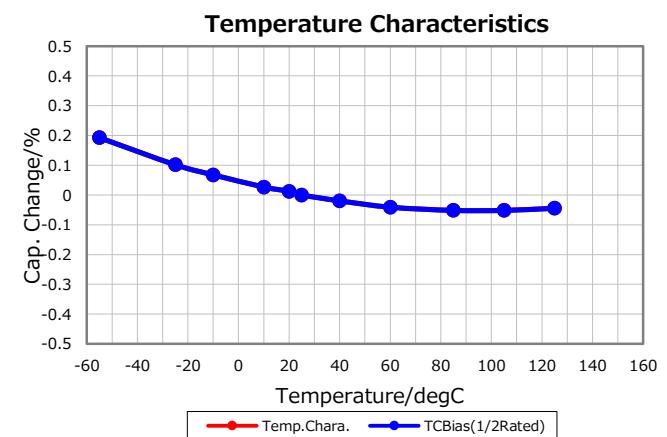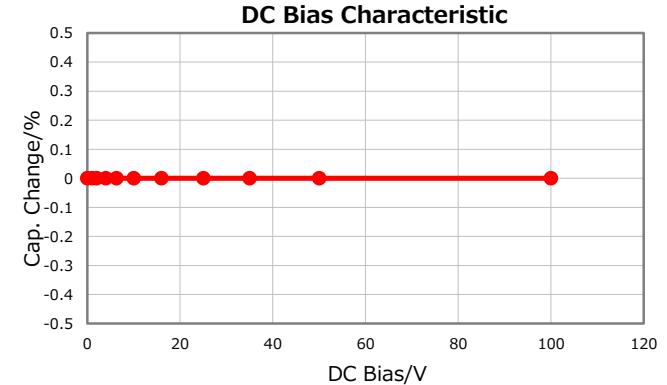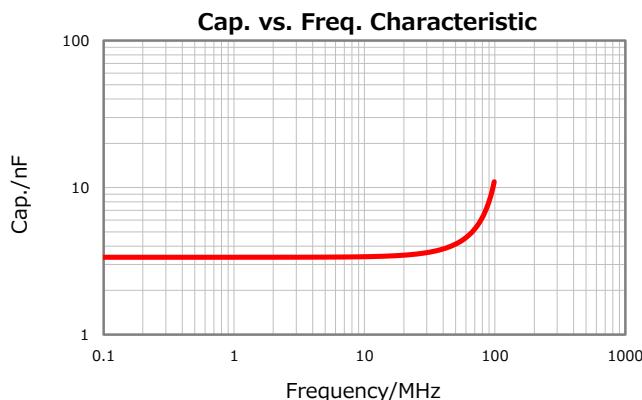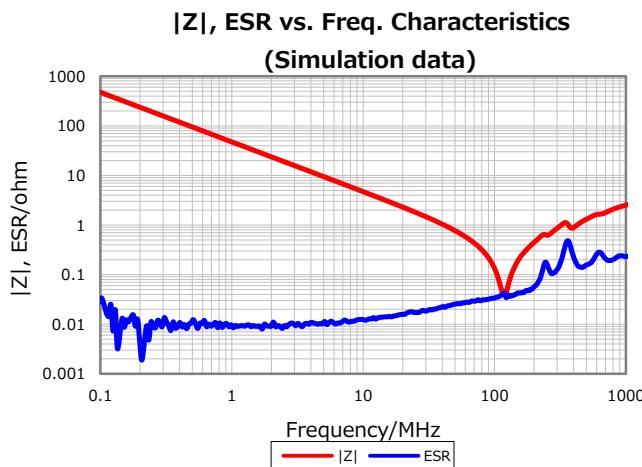

All specifications are subject to change without notice.