

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [0533072871](#)  
**Status:** **Active**  
**Overview:** SlimStack Board-to-Board/Board-to-FPC Connectors  
**Description:** SlimStack Board-to-Board Connector, 0.80mm Pitch, Plug, 4.50 or 5.50mm Mated Height, 28 Circuits, Vertical, without Boss

**Documents:**

<a href="#">3D Model</a>	<a href="#">Packaging Specification SPK-53307-001-001 (PDF)</a>
<a href="#">3D Model (PDF)</a>	<a href="#">Datasheet (PDF)</a>
<a href="#">Drawing (PDF)</a>	<a href="#">Product Guide (PDF)</a>
<a href="#">Product Specification PS-52465-015-001 (PDF)</a>	<a href="#">RoHS Certificate of Compliance (PDF)</a>
<a href="#">Product Specification PS-52588-031-001 (PDF)</a>	<a href="#">Reference Guide (PDF)</a>
<a href="#">Product Specification PS-52588-032-001 (PDF)</a>	


**General**

Product Family	PCB Headers
Series	53307
Application	Board-to-Board, Signal
Component Type	PCB Header
Overview	<a href="#">SlimStack Board-to-Board/Board-to-FPC Connectors</a>
Product Name	SlimStack
Series Name	0.8 and above
Taxonomy	Board-to-Board Connectors
UPC	822348180523

**Physical**

Breakaway	No
Circuits (Loaded)	28
Circuits (maximum)	28
Color - Resin	Natural
First Mate / Last Break	No
Glow-Wire Capable	No
Guide to Mating Part	No
Keying to Mating Part	None
Lock to Mating Part	None
Mated Height	4.50mm, 5.50mm
Mated Width	5.10mm, 7.20mm
Material - Metal	Phosphor Bronze
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Material - Resin	High Temperature Thermoplastic
Net Weight	382.800/mg
Number of Rows	2
Orientation	Vertical
PCB Locator	No
PCB Retention	None
Packaging Type	Embossed Tape on Reel
Pitch - Mating Interface	0.80mm
Pitch - Termination Interface	0.80mm
Plating min - Mating	3.048µm
Plating min - Termination	3.048µm
Polarized to PCB	No
Shrouded	Fully
Temperature Range - Operating	-40° to +105°C
Termination Interface: Style	Surface Mount

**Electrical**

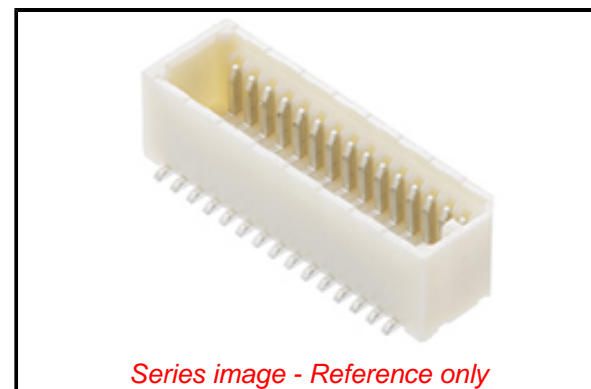

*Series image - Reference only*

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant**

**REACH SVHC**

Not Contained Per -  
D(2022)4187-DC (10  
June 2022)

**Halogen-Free**

**Status**

**Not Low-Halogen**

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

**China RoHS**

Green Image

Not Relevant

Not Contained

**Search Parts in this Series**

[53307 Series](#)

**Mates With**

Board-to-Board Receptacle [52465](#) , [52588](#)

Current - Maximum per Contact 0.5A  
Voltage - Maximum 50V

**Material Info**

**Reference - Drawing Numbers**

Packaging Specification SPK-53307-001-001  
Product Specification PS-52465-015-001, PS-52588-031-001,  
PS-52588-032-001  
Sales Drawing SD-53307-014-001, SD-53307-015-001

This document was generated on 01/25/2023

**PLEASE CHECK [WWW.MOLEX.COM](http://WWW.MOLEX.COM) FOR LATEST PART INFORMATION**