


### C4BC10UXXX

(M12 Cordset, 4 Position, 22 AWG Unshielded, Male Right Angle to Female Straight)

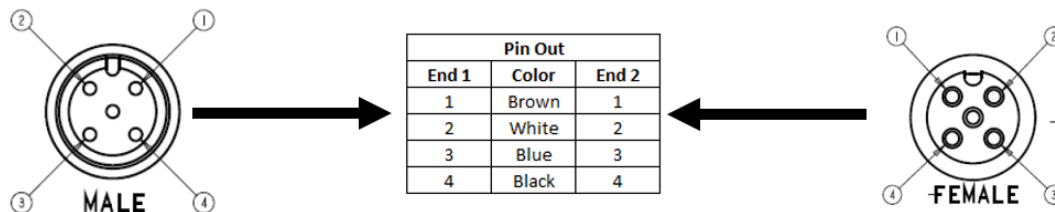

- Mueller's C4BC10UXXX is an M12 4-pin double ended, unshielded instrumentation cable with a right-angle male connector on one end and a straight female connector on the other.
- Keyway – A Coding
- Utilizes a 4-conductor 22 AWG PVC-insulated, unshielded cable.
- Ratings:
  - Current: 4 A
  - Voltage: 250 V AC/DC
- Material:
  - Coupling Nuts – Nickel Plated Brass
  - Pins/Contacts – Gold Plated Brass
- Length: The "U" in the model number represents unit of measurement.  
Either: Meters (M), Feet (F)
- Length: The "XXX" in the model number represents length. Standard lengths are 2, 5, and 10 meters. Any other lengths available upon request.
- Meets Standard: IEC 61076-2-101
- Protection Class: IEC IP68
- RoHS 3 Compliant