


C5C11UXXX

(M12 Cordset, 5 Position, 22 AWG Unshielded, Female Straight to Free End)

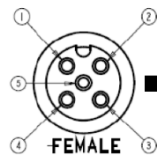

Pin Out		
End 1	Color	End 2
1	Brown	Free End
2	White	
3	Blue	
4	Black	
5	Grey	

- Mueller's C5C11UXXX is an M12 5-pin single ended, unshielded instrumentation cable with a straight female connector on one end and free at the other.
- Keyway – A Coding
- Utilizes a 5-conductor 22 AWG PVC-insulated, unshielded cable.
- Ratings:
 - Current: 4 A
 - Voltage: 250 V AC/DC
- Material:
 - Coupling Nuts – Nickel Plated Brass
 - Pins/Contacts – Gold Plated Brass
- Length: The "U" in the model number represents unit of measurement. Either: Meters (M), Feet (F)
- Length: The "XXX" in the model number represents length. Standard lengths are 2, 5, and 10 meters. Any other lengths available upon request.
- Meets Standard: IEC 61076-2-101
- Protection Class: IEC IP68
- RoHS 3 Compliant