

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [2196542124](#)
Status: **Active**
Overview: [Off-the-Shelf Pre-Crimped Leads](#)
Description: Pre-Crimped Lead Micro-One Female-to-Micro-One Female, Matte Tin Plating, 300.00mm Length, 22 AWG, Red

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Datasheet \(PDF\)](#)

General

Product Family	Cable Assemblies
Series	219654
Application	Signal, Wire-to-Board
Assembly Configuration	Pre-crimped Lead Only
Connector to Connector	Micro-One-to-Micro-One
Overview	Off-the-Shelf Pre-Crimped Leads
Product Name	Micro-One
Taxonomy	Power and Signal Cable Assembl
UPC	195842803800

Physical

Cable Length	300.00mm
Circuits (Loaded)	1
Color - Resin	Red
Gender	Female-Female
Material - Metal	Copper Alloy
Material - Plating Mating	Matte Tin
Net Weight	1.728/g
Packaging Type	Bag
Plating min - Mating	0.900µm
Plating min - Termination	0.900µm
Single Ended	No
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	1.10-1.60mm
Wire Size AWG	22
Wire/Cable Type	UL 1569


Electrical

Current - Maximum per Contact	4.0A
Voltage - Maximum	250V AC (RMS)/DC

Material Info

Reference - Drawing Numbers

Sales Drawing	2196541121-000
---------------	----------------

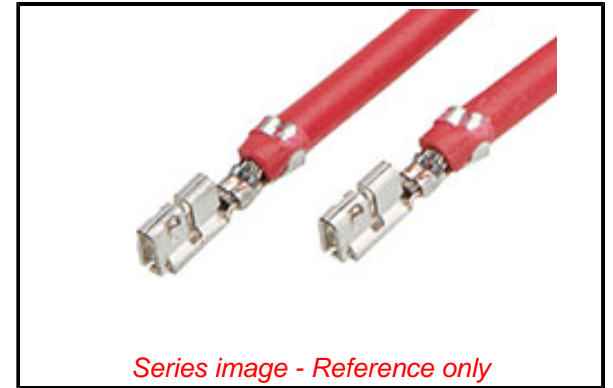

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained per -
D(2022)9120-DC (17
Jan 2023)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[219654](#) Series

Use With

Micro-One Receptacle Housing [205979](#) ,
[212724](#)